


Presse-étoupe SIB-TEC Polyamide

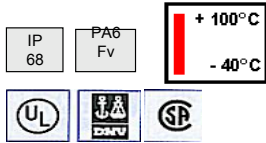

Matière:

- Polyamide 6 V2 suivant UL 94

- Garniture: Neoprène

Caractéristiques:

- filetage : GUIDE UTE 68310 / GUIDE UTE 68311
- filetage PG
- avec garniture réductrice
- IP 68 sans joint

Propriétés spécifiques:

- exempt d'halogène
- avec gamme de serrage élargie par lamelles
- conforme RoHS

Application:

- machines et accessoires

SIB-TEC Cable gland Polyamide

Material:

- Polyamide 6 V2 according to UL 94

- Seal: Neoprene

Characteristics:


- threads: GUIDE UTE 68310 / GUIDE UTE 68311
- PG thread
- with reducer-seal insert
- IP 68 without seal

Features:

- free of halogen
- wide clamping range through clamp lamella
- according to RoHS

Applications:

- machines and devices

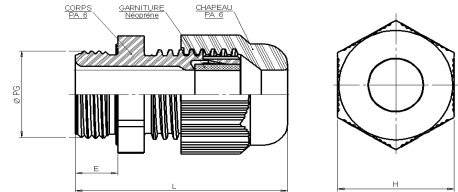

Filetage	Type	Capacité	H	E	L	Art.-Nr.	Art.-Nr.	Colisage
		mm	mm	mm	mm			
Thread	Type	clamping range	SW	E	L	gris foncé	noir	
			H	mm	mm	Art.-No.	Art.-No.	Packing
		mm	mm	mm	mm	silver grey	jet black	
PG 07	court / short	2,5 - 6,5	15	8	32	F7000700	F8000700	50
PG 09	court / short	2,5 - 8,0	19	8	35	F7000900	F8000900	50
PG 11	court / short	3,5 - 10,0	22	8	37	F7001100	F8001100	50
PG 13,5	court / short	5,0 - 12,0	24	9	39	F7001300	F8001300	50
PG 16	court / short	7,0 - 14,0	27	10	43	F7001600	F8001600	50
PG 21	court / short	9,0 - 18,0	33	11	50	F7002100	F8002100	20
PG 29	court / short	14,0 - 25,0	42	11	53	F7002900	F8002900	20
PG 36	court / short	18,0 - 32,0	53	13	65	F7003600	F8003600	10
PG 42	court / short	24,0 - 38,5	60	13	68	F7004200	F8004200	5
PG 48	court / short	35,0 - 48,0	70	14	70	F7004900	F8004900	5
PG 07	avec garniture réductrice / with reducer-seal insert	1,5 - 5,0	15	8	32	F7000740	F8000740	50
PG 09	avec garniture réductrice / with reducer-seal insert	1,5 - 6,0	19	8	35	F7000940	F8000940	50
PG 11	avec garniture réductrice / with reducer-seal insert	2,0 - 7,0	22	8	37	F7001140	F8001140	50
PG 13,5	avec garniture réductrice / with reducer-seal insert	3,0 - 9,0	24	9	39	F7001340	F8001340	50
PG 16	avec garniture réductrice / with reducer-seal insert	5,0 - 12,0	27	10	43	F7001640	F8001640	50
PG 21	avec garniture réductrice / with reducer-seal insert	7,0 - 16,0	33	11	50	F7002140	F8002140	20
PG 29	avec garniture réductrice / with reducer-seal insert	11,0 - 21,0	42	11	53	F7002940	F8002940	20
PG 36	avec garniture réductrice / with reducer-seal insert	13,0 - 26,0	53	13	65	F7003640	F8003640	10
PG 42	avec garniture réductrice / with reducer-seal insert	17,0 - 31,0	60	13	68	F7004240	F8004240	5
PG 48	avec garniture réductrice / with reducer-seal insert	26,0 - 39,0	70	14	70	F7004940	F8004940	5

PE disponible en RAL 7001 / RAL 7001 cable gland available on req.

