


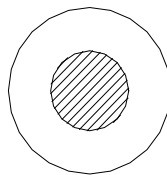

Product Name:	MIL-W-16878/6 26AWG
Product Discription:	MIL-W-16878/6 26AWG
Specification No.:	
Customer's Name:	

Description					Construction							
Rated Voltage:		250V			Conductor		Stranded Sliver plated copper					
Rated Temperature:		200℃			Size(AWG)		26					
Reference Standard:		MIL-W-16878/6			Construction(±0.008mm)		19/0.10					
Cross Section					Stranded Dia.(mm)Ref.		0.5					
					Insulation Material		PTFE					
					Insulation Color		ANY COLOR					
					Ave Thickness(mm)		0.15					
					Insulation Dia.(±0.08mm)		0.80					
Marking					Remark: 8775496 Red 8775493 Blue 8775480 Black 8775490 White 8775484 Brown							
No marking on the cable jacket												
Applications					Characteristics				Customer Approve			
These wires are ideal for internal wiring of appliances, electronic equipment and other applications.					Test Item			Standard Value			Seal & Stamp	
					Test Material			PTFE(ROHS)				
					Insulation resistance(20℃ MΩ*m			1000				
					Vol. Tesr(AC.V.60S) (V)			2000				
					Flammability Test			VW-1				
Revisions					Max.DC Resistance(20℃ Ω/km)			122.37(MAX)				
Version	Description		Drawn by	Approved by	Date							
0	New document issue		Danniel	Jason	19/05/2015							