



## PPS1 CI - Collier de fixation

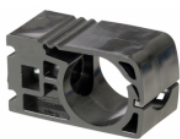


**Ø 16 - 32**

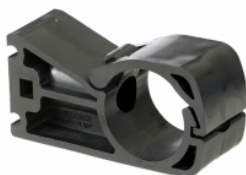

**Ø 40 - 100**

Description		
Référence	Pour tube Ø ext. (mm)	Filetage
<b>PPS1 CI16</b>	16	M8
<b>PPS1 CI20</b>	20	M8
<b>PPS1 CI25</b>	25	M8
<b>PPS1 CI32</b>	32	M8
<b>PPS1 CI40</b>	40	M8
<b>PPS1 CI50</b>	50	M8
<b>PPS1 CI63</b>	63	M8

Référence	Pour tube Ø ext. (mm)	Filetage
PPS1 CI80	80	M8
PPS1 CI100	100	M8

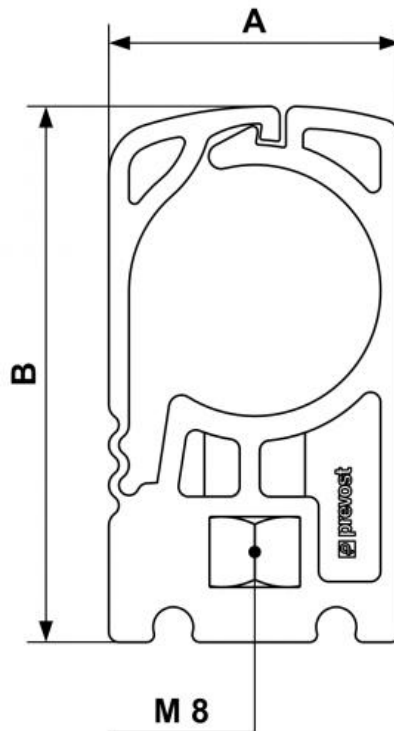

Dimensions		
Référence	A mm	B mm
PPS1 CI16	24	47
PPS1 CI20	24	49
PPS1 CI25	29	53
PPS1 CI32	38	57

Référence	A mm	B mm
<b>PPS1 CI40</b>	49	99,5
<b>PPS1 CI50</b>	59	104,5
<b>PPS1 CI63</b>	75	135
<b>PPS1 CI80</b>	90	145
<b>PPS1 CI100</b>	110	155