


Grey Soft Rubber Trolley Wheel 75mm, 50kg

Thermoplastic rubber-tyred wheel

PRODUCT

Article number

380 517

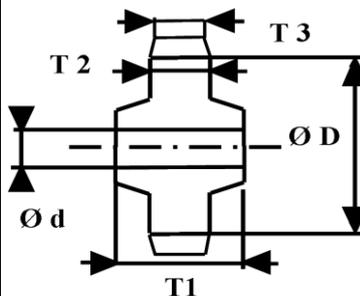

Product Details

Wheel Rim : made of grey impact-resistant polypropylene.
 Tread : grey thermoplastic rubber, integrated type. Non-marking.
 Hub : symmetrical with plain bore and steel threadguards.
 Delivered with M6x40 bolt

Specifications

Wheel Diameter - ØD ± 1%	75 mm
Hub Type	Plain
Hub Length T1	25 mm ±1
Width of Tread T2	21 mm ±1
Width of Tread-on floor T3	21 mm ±1
Axle Hole Ø d	Ø 10 mm
Hardness of tread A ±3	A 80° Shore
Load capacity	50 Kg
Temperature	-10 / +50 °C
Bolt	Hexagonal Head M6X40
Weight	0,08 Kg

TECHNICAL DATA

Applications :

Quiet and non-marking materials handling.
 Lightweight, low starting effort.
 Suitable for all interiors floors (warehouses, offices, shops, kitchens,...).
 Smooth and silent movement thanks to the shock-absorbing tread.