



KX3 RIPSTOP TROUSERS

DESCRIPTION

Contemporary work trouser made from highly durable ripstop fabric that stretches as you move. Subtle articulation on the knees allow for increased freedom of movement and a high rise back waistband ensures protection in all working positions. Packed with functionality including pre-bent knees, a crotch gusset, two tier knee pad pockets and an adjustable leg length for added convenience. Multi-functional thigh pockets provide secure storage of phones, pens and tools.

COMPOSITION

 **Titanmill Plus Ripstop: 65% Polyester, 35% Cotton Ripstop Weft Stretch, 230g**
 **Metal Grey 28-48**

FEATURES

- Stretch ripstop provides superior comfort and increased freedom of movement
- Webbing belt loops for extra durability
- Bottom loading knee pad pockets
- Lower back leg pocket provides quick access whilst kneeling and bending
- Pre-bent knees allow for increased freedom of movement
- 14 pockets for ample storage
- 2 Side pockets
- 2 Back pockets
- 2 side zip pockets for secure storage
- 1 Phone pocket
- 2 Zipped thigh pockets
- 1 Lower leg pocket


STANDARDS

EN 14404: 2004 + A1: 2010 Type 2 Level 0 (When used in combination with S156)

COLOUR / SIZES

SKU	COLOUR	SIZE RANGE
T802MGR	METAL GREY	28-14

FEATURES

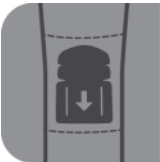

BOTTOM LOADING KNEE PAD POCKETS
Knee pad pockets to facilitate knee pads



UPF 40+
40+ UPF rated fabric to block 98% of UV rays



14 POCKETS
14 pockets for ample storage



ACTIVE STREET WORKWEAR
Active Street Workwear using technical fabrics designed around comfort and performance.

GET THE COLLECTION



TECHINCAL INFORMATION



- Wash dark colours separately
- Wash garment inside out
- Wash garment inside out and fully fastened
- Wash with similar colours

Item	Colour Fit	Len (cm)	Wid (cm)	Hgt (cm)	Weight (Kg)	Cubic (m³)	EAN13	GTIN/DUN14
T802MGR28	Metal Grey	43	28	40	.782	2006.666	5036108441730	25036108928976
T802MGR30	Metal Grey	43	28	40	.782	2006.666	5036108441747	25036108928983
T802MGR32	Metal Grey	43	28	40	.782	2006.666	5036108441754	25036108928990
T802MGR33	Metal Grey	43	28	40	.782	2006.666	5036108441761	25036108929003
T802MGR34	Metal Grey	43	28	40	.782	2006.666	5036108441778	25036108929010
T802MGR36	Metal Grey	43	28	40	.782	2006.666	5036108441785	25036108929027
T802MGR38	Metal Grey	43	28	40	.782	2006.666	5036108441792	25036108929034
T802MGR40	Metal Grey	43	28	40	.782	2006.666	5036108441808	25036108929041
T802MGR41	Metal Grey	43	28	40	.782	2006.666	5036108441815	25036108929058
T802MGR42	Metal Grey	43	28	40	.782	2006.666	5036108441822	25036108929065
T802MGR44	Metal Grey	43	28	40	.782	2006.666	5036108441839	25036108929072
T802MGR46	Metal Grey	43	28	40	.782	2006.666	5036108441846	25036108929089
T802MGR48	Metal Grey	43	28	40	.782	2006.666	5036108441853	25036108929096