


FAST SANDING OF PAINT AND WOOD

EXPERT C470 Sandpaper

EXPERT

- ① Exceptional abrasion with Bosch Surface Structure
- ② Grain alignment during production ensures aggressive cut
- ③ Grain distribution optimised for high-speed sanding

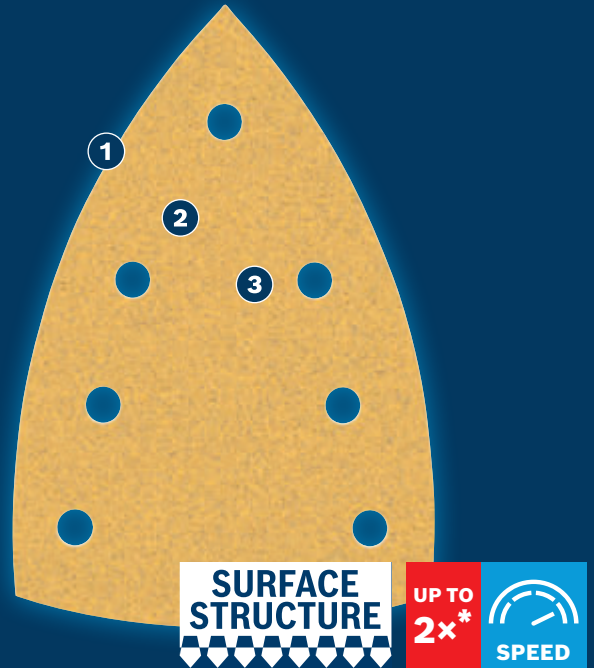


* vs. Bosch C420



BOSCH

EXPERT C470 SANDPAPER

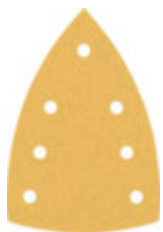

- ▶ Ideal for highly effective fast sanding of flat surfaces; to remove old paint; or to smooth, prepare and finish surfaces
- ▶ EXPERT Abrasives - the very best for all trades
- ▶ Up to 2x faster than Bosch C420 Sandpaper
- ▶ Just stick it on with hook and loop



PRODUCT PROPERTIES			ORDERING INFORMATION				
Sheet dimensions mm	Grit	Perforation	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...	Part number
100x150	40	7 holes	C1a	10	5	544 526	2 608 901 114
100x150	60	7 holes	C1a	10	5	544 533	2 608 901 115
100x150	80	7 holes	C1a	10	5	544 540	2 608 901 116
100x150	120	7 holes	C1a	10	5	544 557	2 608 901 117
100x150	180	7 holes	C1a	10	5	544 564	2 608 901 118
100x150	240	7 holes	C1a	10	5	544 571	2 608 901 119
100x150	320	7 holes	C1a	10	5	545 042	2 608 901 166
100x150	400	7 holes	C1a	10	5	545 059	2 608 901 167
100x150	40	7 holes	C0a	50	1	635 903	2 608 901 640
100x150	60	7 holes	C0a	50	1	635 910	2 608 901 641
100x150	80	7 holes	C0a	50	1	635 927	2 608 901 642
100x150	120	7 holes	C0a	50	1	635 934	2 608 901 643
100x150	180	7 holes	C0a	50	1	635 941	2 608 901 644
100x150	240	7 holes	C0a	50	1	635 958	2 608 901 645



BOSCH