


Wiring duct 37.5x50 mm, 2000 mm, PVC, grey

Art.-No. 185-40188 | HTWD-DIN 37.5X50-PVC-GY | 

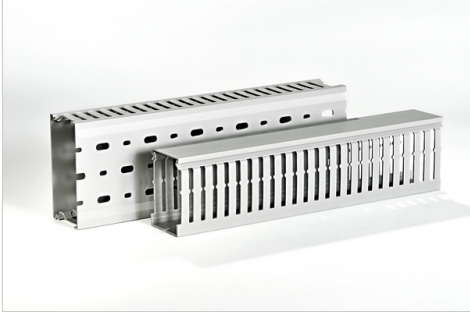


- Narrow slots suitable for small-diameter wires
- Smooth, burr-free edges protect installers from injury and wires from damage
- Fingers can be removed with no sharp edges at pre-notched snap-off points
- Further pre-notched snap-off point at base of sidewall allow cutting out and removing sections of sidewall with no sharp edges
- Duct covers are easy to mount and remove, yet hold securely even in a vertical position and under vibration
- Cover is flush with side of duct, allowing for tight, contiguous
-



Application	Heladuct HTWD-PD wiring ducts are used to route and protect wires in control panels and switching systems.
Colour	Grey (GY)
Current leak stable Yes/No	Yes
Fixation Method	Screw Mounting
Material	Polyvinylchloride (PVC)
PART DESCRIPTION	HTWD-DIN 37.5X50-PVC-GY
Pack Content	32 m
Package Content packed in	box
Type	HTWD-DIN 37.5X50
Type of side wall	Slotted


Product Dimensions

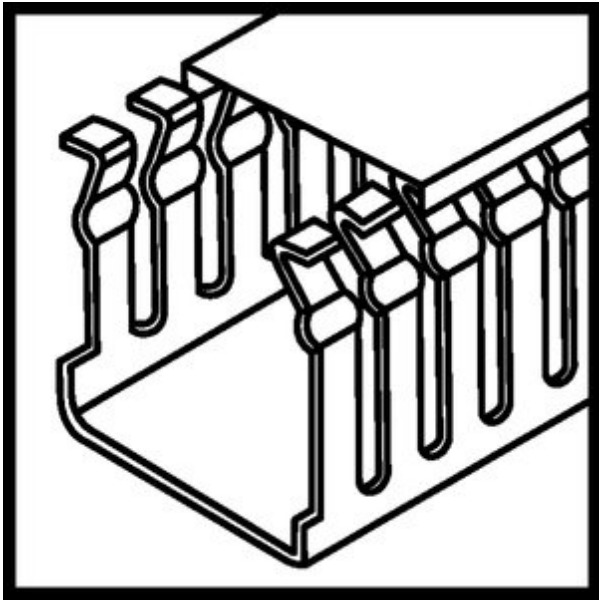

Height (H)	50 mm
Length (L)	2000 mm
Suitable for cross section	1275 mm ²
Width (W)	37.5 mm
Width (W2)	5 mm
Width (W3)	7.5 mm

ELV compliant (Article 4 - 2)	YES
Flammability	UL 94 V0
Hazardous Goods	No
Operating Temperature	-20 °C to +60 °C
ROHS compliant	Yes
Specifications	RoHS
Specifications	EN 50085-25, UL
UL Listed (US and Canada)	Yes
UL Listed (US and Canada)	No
UL-File Number	E357929

Logistics and Packaging

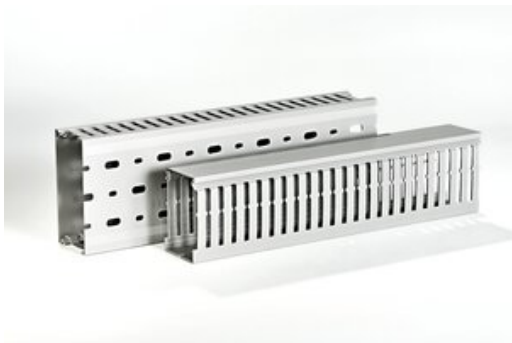

GTIN-13 / EAN	4031026427881
Packaging 3 - Height (m)	0.18 m
Packaging 3 - Length (m)	2.03 m
Packaging 3 - Qty	32
Packaging 3 - Type	carton
Packaging 3 - Volume (m³)	0.0658 m³
Packaging 3 - Weight (kg)	12.02 kg
Packaging 3 - Width (m)	0.18 m
Packaging 4 - Height (m)	1.045 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	800
Packaging 4 - Type	pallet
Packaging 4 - Volume (m³)	1.003 m³
Packaging 4 - Weight (kg)	340.5 kg
Packaging 4 - Width (m)	0.8 m

