


ENCLOSED HOSE REELS FOR COMPRESSED AIR / STEEL

DSF Series - Small - Polyurethane hose polyester base



Part number	Length (m)	Flow rate (l/min)	Temperature min/ max (°C)	Max. operating pressure (bar)	Net weight (Kg)	Profile
DSF 0805ES	5.00	650.00	-15.00 / 40.00	12.00	3,159	EUROPEAN
DSF 1003ES	3.00	1100.00	-15.00 / 40.00	12.00	3,041	EUROPEAN
DSF 0805BS	5.00	650.00	-15.00 / 40.00	12.00	3,1	BRITISH
DSF 1003BS	3.00	750.00	-15.00 / 40.00	12.00	3,05	BRITISH

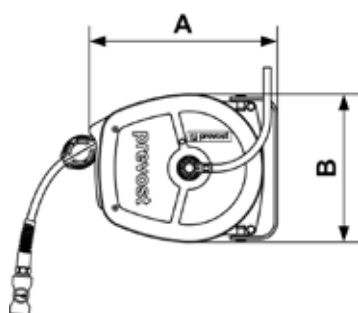

Part number	Dim. A (mm)	Dim. B (mm)	Ø int/ext (mm)
DSF 0805ES	275.00	218.00	8.00 / 11.00
DSF 1003ES	275.00	218.00	10.00 / 14.00
DSF 0805BS	275.00	218.00	8.00 / 11.00
DSF 1003BS	275.00	218.00	10.00 / 14.00