


Datasheet

RS Pro 6 Port Sensor Box with 5 Way M12 Sockets

RS Stock No: **877-1227**



Wire Connection

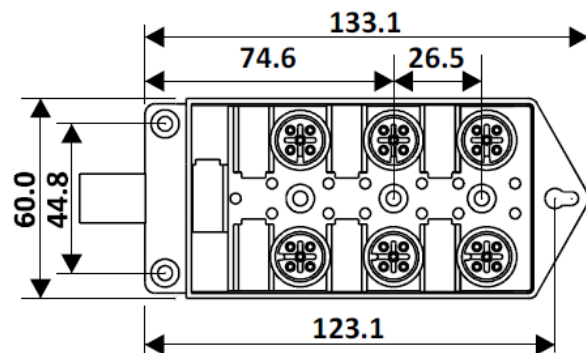

Product Details

RS Pro sensor box has 6 ports and compatible 5-way M12 pin connector. It has selection of splitter boxes for M12 connecting leads, for use with sensor and automation equipment. With an excellent degree of environmental protection, this I/O junction box is suitable for harsh industrial conditions.

Features and Benefits

- Nickel plated brass contacts
- MODBUS and zigbee wireless models protected to IP55
- Wired and terminal block models protected to IP65/IP67
- PBT plastic housing
- Operating temperature range of 0 to +55°C
- Neoprene O-Ring

**Specifications:**

Cable Length	5 m		
Compatible Connector	5-Pin M12		
Connector Size	M12		
Control Cable Connector	M12		
Number of Ports	6		
Number of Ways	5	Connection Type	Cable
Housing Material	PBT Plastic		
IP Rating	IP65, IP67		
Operating Temperature Range	0 to +55°C		
Rated Current	2 A		
Supply Voltage	24 V dc		