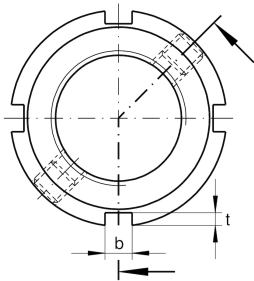
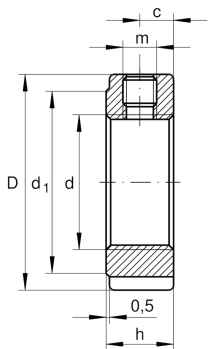
**ZM70** **Precision locknut**

Precision locknut ZM, accessory ZM..

Technical information**Main Dimensions & Performance Data**

d	M70X2	Thread
D	92 mm	Outside diameter
h	18 mm	Height
M _A	15 Nm	Mounting torque set screw
F _{aB}	305,000 N	Breaking load, axial
M _L	220 Nm	Breakawag
M _{AL}	130 Nm	Mounting torque reference
M _M	6.61 kg*cm ²	Mass moment of inertia
≈m	381.33 g	Weight

Dimensions

d ₁	85 mm	Plant diameter outside
t	3.5 mm	Hight retaining slot
b	8 mm	Width retaining slot
c	9 mm	Distance bore
m	M8	Threaded - threaded pin