


DATASHEET

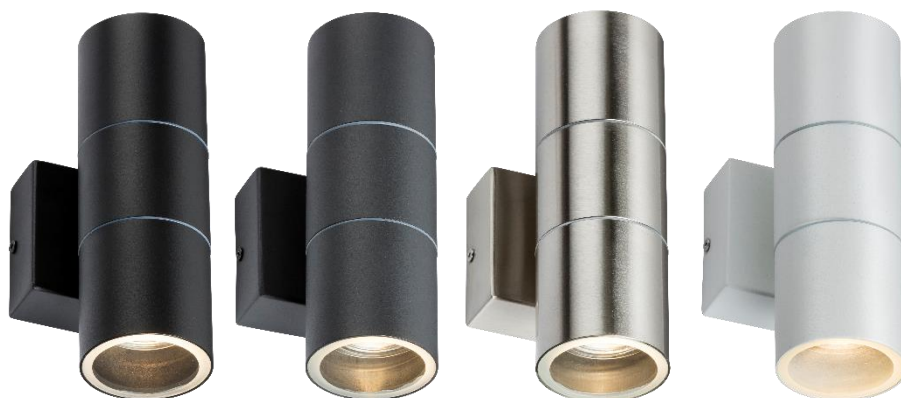

OWALL2xx

230V IP54 GU10

Up / Down Wall Light

www.mlaccessories.co.uk

MLA PART CODE	OWALL2BK	OWALL2A	OWALL2BC	OWALL2W
DESCRIPTION	230V IP54 GU10 Up / Down Wall Light			
FINISH	Black	Anthracite	Brushed Chrome	White
NETT WEIGHT (KG)	0.71			
DIMENSIONS (MM)	Body Diameter – 60 Body Height - 170 Base Height – 71 Base Width - 81 Projection – 96			
MAX WATTAGE (W)	2 x 20			
LAMP BASE	GU10			
LAMP TYPE	Halogen / LED Compatible			
INPUT VOLTAGE	Mains 230V 50Hz			
CONSTRUCTION	Stainless Steel			
CLASS	Class I			
IP RATING	IP54			
DIMMABLE	Dependent on lamp			
WARRANTY	2 Years			
ORIGIN OF MANUFACTURE	China			
DECLARATION OF CONFORMITY (HELD ON FILE)	Yes			
MANUFACTURED IN ACCORDANCE WITH	BS EN 60598			
EAN	5056270818635	5056270818642	5056270818659	5056270818666



AKOCT20_V1

