



Datasheet

Stock No. 1881770, 1882212

RS PRO Piezo Buzzer



ENGLISH



Specifications



Rated voltage	12VDC
Operating voltage	1-18VDC
Rated current*	≤20mA
Sound output at 10cm*	≥85dB
Resonant frequency*	4000±500Hz
Tone	Continuous
Operating temperature	-30~+70°C
Storage temperature	-40~+85°C
Weight	2.5g

*Value applying at rated voltage (DC)

All data at 25°C unless otherwise specified

Features

- ROHS compliant
- Lead pin material: Red Copper
- Housing material: Noryl
- Wave solderable but not washable

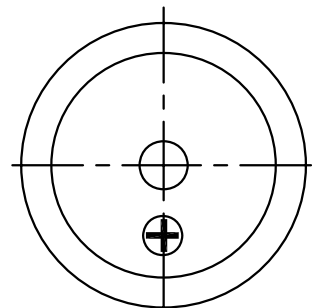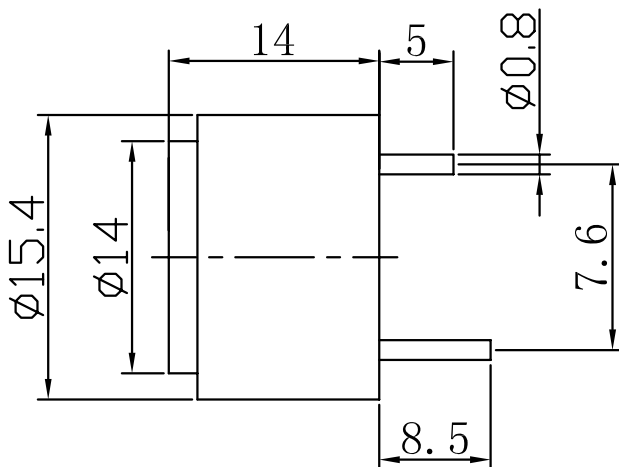

Dimensions Unit: mm Tolerance: ±0.5mm