




The universal 90° connection – die-cast aluminium Fastener D30 produces a lasting hold with no creep behaviour. It creates a mechanically locked connection with the contour of a Profile Tube D30 or Profile 6 D30.

Up to four Fasteners can be connected to intersection points on a Profile Tube. No special fasteners are required! Fastener D30 consists of two half shells that fit around Tubes and Profile Tubes D30 and use external clamping technology to ensure a secure hold.

Fastener D30 is supplied preassembled, which saves time on assembly operations. The connection is secure as soon as the screw fixing is tightened, meaning one person can build a frame independently.

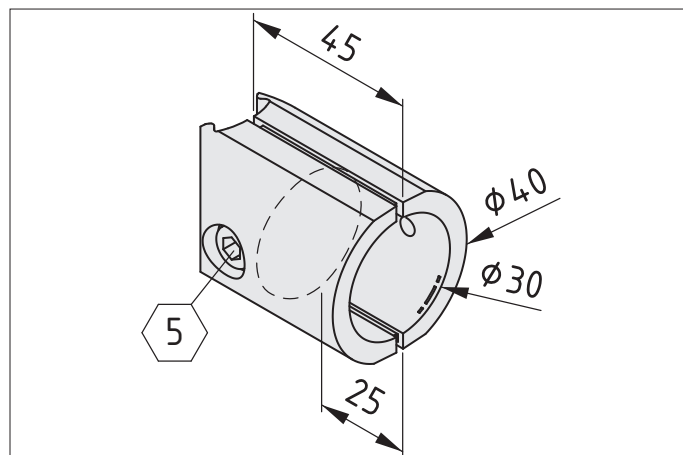

Scope of Delivery

Preassembled
2 fastener halves, die-cast Al, natural
Hexagon Socket Head Cap Screw similar to DIN 912 M6x29.4, St, bright zinc-plated
Hexagon nut DIN 934 M6-l8l, St, bright zinc-plated

Technical note

[0.0.623.56](#) Please click here for further information!

Properties	
Article number	0.0.623.56
Delivery unit	1 pce.
Status on delivery	Preassembled
Weight	105.0 g
Torque	10 Nm

Accessoires	
0.0.624.11	Cap D30 R, grey similar to RAL 7042
0.0.630.39	Anti-Torsion Block 6 D30, grey similar to RAL 7042
0.0.630.40	Anti-Torsion Block 6 D30-45°, grey similar to RAL 7042
0.0.642.62	Adapter D30/D28-25, grey similar to RAL 7042
0.0.630.51	Adapter 8 D30
0.0.630.61	Tube Adapter D30
0.0.653.24	Adapter 8 80 D30
0.0.725.24	Profile 8 40x40 1N D30 light, natural
0.0.026.29	Key with T-Handle 5 A/F