

 
+FLEX 80

IP20 Flexible LED Tape



Product Features

- Available in four different colour temperatures
- Industrial grade adhesive backing tape
- Bespoke design and cutting service available
- Operating temperature -20°C ~ +45°C
- Humidity 40% - 70% RH
- High efficacy
- 3 years warranty



Specifications

Stock Code	1153-906 	0681-235 	1328-981 	0957-991 
Part Code	B7-2-80-20	C0-2-80-20	D0-2-80-20	F0-2-80-20
Voltage	24VDC	24VDC	24VDC	24VDC
Power Consumption	4W/m	4W/m	4W/m	4W/m
Lumen Output	630lm/m	650lm/m	665lm/m	665lm/m
Efficacy	158lm/W	162lm/W	166lm/W	166lm/W
Colour Temperature	2700K	3000K	4000K	6000K
LED/metre	80	80	80	80
LED Pitch	12.5mm	12.5mm	12.5mm	12.5mm
Cut Points	100mm	100mm	100mm	100mm
CRI (Ra)	>80	>80	>80	>80
IP Rating	IP20	IP20	IP20	IP20
Dimensions	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm	5000 x 8 x 1.2mm




2700K



3000K



4000K

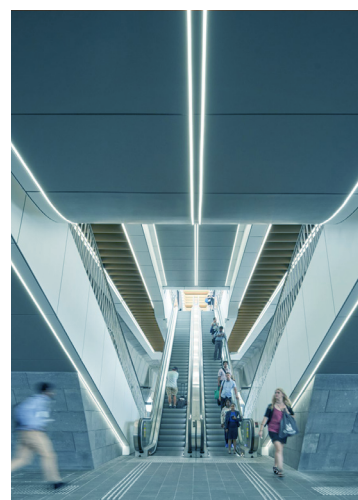


6000K




+FLEX 80

IP65 Flexible LED Tape

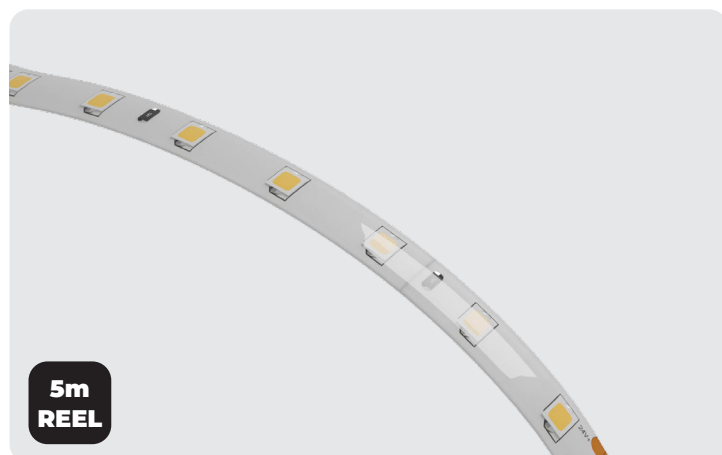

Product Features

 - Available in three different colour temperatures
- Industrial grade adhesive backing tape
- Bespoke design and cutting service available
- Operating temperature -20°C ~ +45°C
- Humidity 40% - 70% RH
- High efficacy
- 3 years warranty



Specifications

Stock Code	0302-311 	0654-364 	1790-920 
Part Code	C0-2-80-65	D0-2-80-65	F0-2-80-65
Voltage	24VDC	24VDC	24VDC
Power Consumption	4W/m	4W/m	4W/m
Lumen Output	592lm/m	592lm/m	605lm/m
Efficacy	148lm/W	148lm/W	151lm/W
Colour Temperature	3000K	4000K	6000K
LED/metre	80	80	80
LED Pitch	12.5mm	12.5mm	12.5mm
Cut Points	100mm	100mm	100mm
CRI (Ra)	>80	>80	>80
IP Rating	IP65	IP65	IP65
Dimensions	5000 x 8 x 2.2mm	5000 x 8 x 2.2mm	5000 x 8 x 2.2mm



3000K



4000K



6000K




+FLEX 80

IP20 & IP65 Flexible LED Tape



Compatibility*

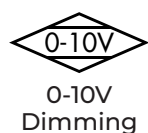

Suggested Drivers

Non-Dimmable

Up to 1m

Power supplied from ONE end
PCV2420

Up to 3m

Power supplied from ONE end
PCV2420

Up to 5m

Power supplied from ONE end
PCV2420

Up to 10m

Power supplied from MIDDLE
PCV2450-REV-A

Mains Dimming

Up to 1m

Power supplied from ONE end
UVC2425TD-REV-A

Up to 3m

Power supplied from ONE end
UVC2425TD-REV-A

Up to 5m


Power supplied from ONE end
UVC2425TD-REV-A

Up to 10m


Power supplied from MIDDLE
UVC2450TD-REV-A

Mechanical Diagram

IP20

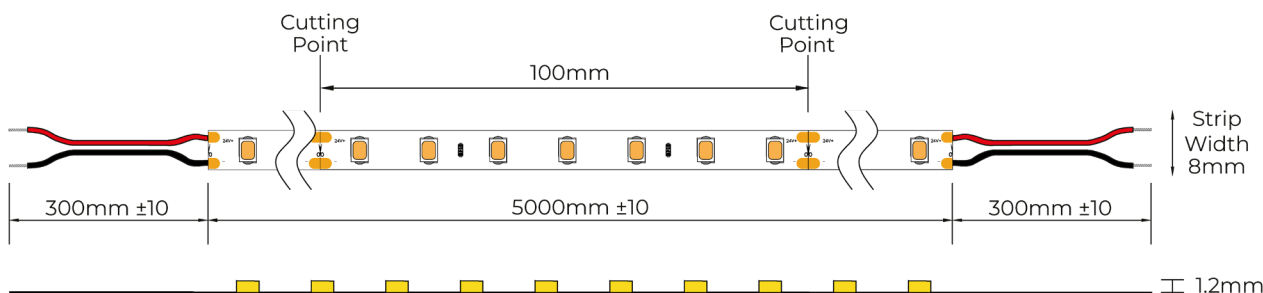

IP65

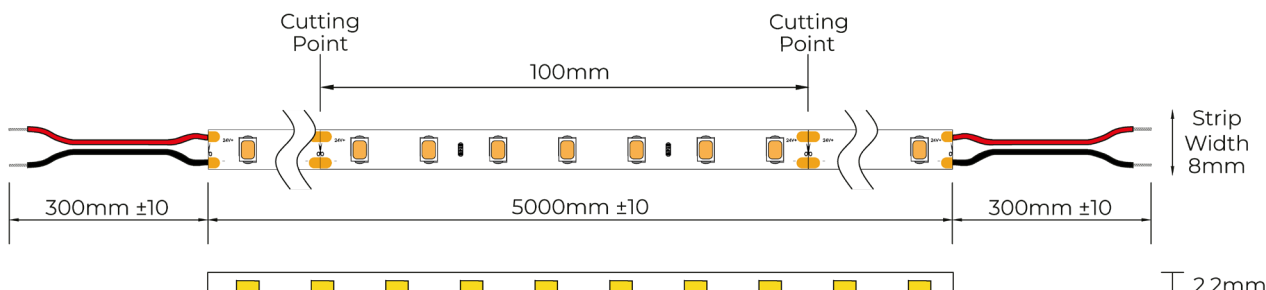

* Product compatibility with other brands is shown for informational purposes only. All third-party company names and logos are trademarks of their respective owners and do not constitute an endorsement or partnership with our company.