



Datasheet


RS PRO 1m VGA/SVGA Low Profile HD15 Male to Female Low Smoke Zero Halogen Cable – Blue

Stock number: 182-8886

EN

Our RS PRO 1 metre monitor cable comes with a low profile high density 15 pin male to a low profile high density 15 pin female connector which is commonly known as a VGA or SVGA connector. It has all pins connected. The jacket and the connector hoods are made of blue, low smoke zero halogen PVC.

The SVGA connector is one of the most common video connectors found on computers. SVGA is an analogue signal which is slowly being replaced by digital cables such as HDMI and Displayport.

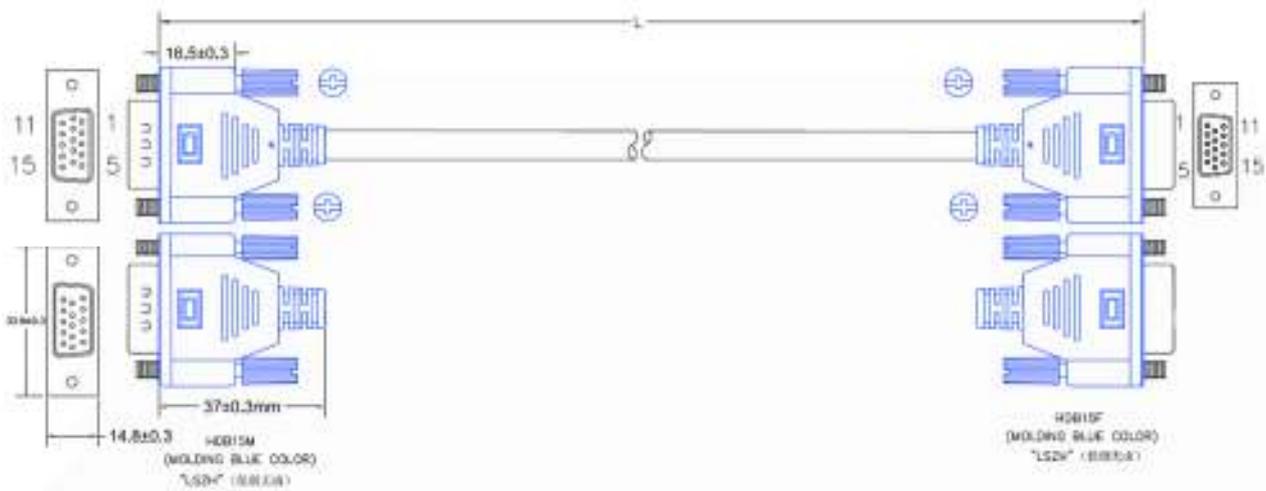

(P1)HDB15M	1	2	3	6+7+8	4	5	9	10	11	12	13	14	15	64
(P2)HDB15F	1	2	3	6+7+8	4	5	9	10	11	12	13	14	15	64
	RC	GC	BC	RG	GG	BG								

1. CABLE: 32AWG,UL20276,AL-FOIL,3COAX+9C,BLUE COLOR,OD=5.5mm,LSZH JACKET(LSZH).
2. LENGTH:L.
3. CONNECTORS:HDB15M*1PCS,HDB15F*1PCS(BLUE INSULATOR)*1PCS(SHELL NICKEL).
4. MOLD:MOLDING TYPE.
5. CONTACTS
6. OPEN/SHORT TEST: 100% TEST.
 - A.100% OPEN,SHORT&INTERMITANCE TEST.
 - B.CONDUCTOR RESISTANCE: 3ohms MAX:
 - C.INSULATION RESISTANCE: 5M Min/,DC300V 10ms:
7. ALL MUST BE MEET ON ROHS COMPLIANT.

RoHS / REACH / CE

