


E40633



Welding adapters EN10357 series D (SMS)

ADAPT EN10357-D DN50

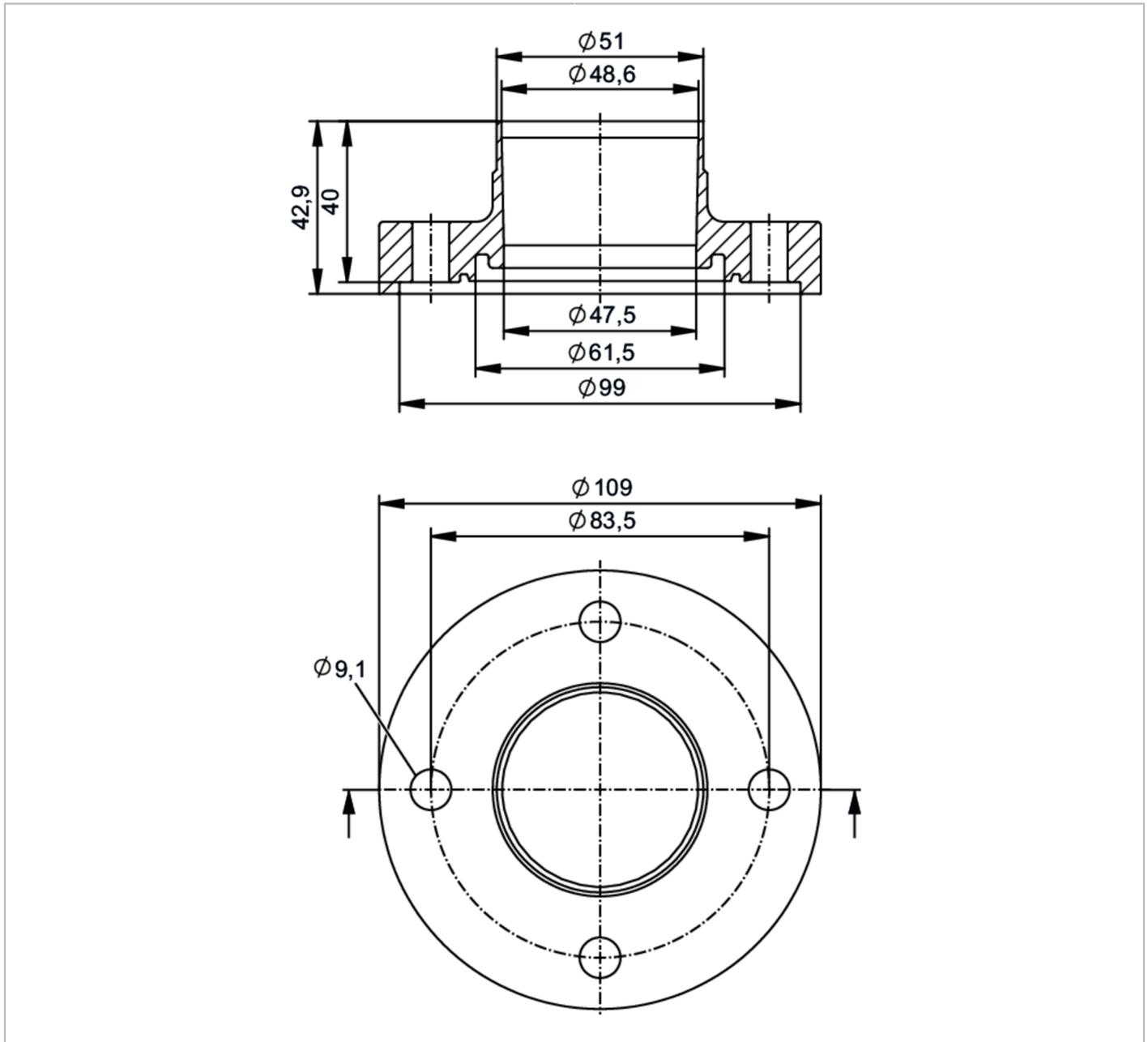

Application	
Design	for volumetric flow meters SMF
Application	food and beverage industry; hygienic systems
Pressure rating	25 bar / 2.5 MPa
Tests / approvals	
Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.
Mechanical data	
Weight	[g] 2544.1

E40633



Welding adapters EN10357 series D (SMS)

ADAPT EN10357-D DN50

Materials	stainless steel (316L/1.4404)
Nominal diameter	DN50 (2")
Sensor connection	ifm-specific device flange
Process connection	welding adapter EN10357 series D (SMS); ISO 2037
Process connection suitable for pipe standard	(DIN EN 10357 Series D); (ISO 2037)
Surface characteristics Ra/Rz of the wetted parts	Ra ≤ 0.4 μm
Accessories	
Items supplied	screws 8
Remarks	
Pack quantity	2 pcs.