



LED exit signs suitable for wall or ceiling mounting

The **Rota** is a superbly designed range of LED Exit Signs, which combines long-life LED Technology with High Quality engineering.

The versatile design of the **Rota** allows wall or ceiling mounting with a range of high quality finishes including white, brass, chrome, black or silver-grey (RAL-9006)

Suitable for non-maintained and maintained modes this 3 hour exit sign also includes a new recessed version suitable for almost any prestigious project.

Both the surface and recessed versions utilise the unique high quality plasi-glas legends with flame polished edges which ensure that the light distribution is effectively and evenly diffused across the legend resulting in a high performance, impressive and reliable emergency luminaire.

Can be used with single and double-sided legends (please specify when ordering)



Rota finished in chrome
Viewing distance
32 metres

Rota recessed
finished
in white



Emergency Luminaires

Cat No.	Mode/Lamp	Lumens	Kg
RO/LED/M3/WH	M3 White LED Exit Sign	-	2.00
RO/LED/M3/BR	M3 Brass LED Exit Sign	-	2.00
RO/LED/M3/CH	M3 Chrome LED Exit Sign	-	2.00
RO/LED/M3/BK	M3 Black LED Exit Sign	-	2.00
RO/LED/M3/SG	M3 Silver Grey LED Exit Sign	-	2.00

* For other durations, specify the required time period e.g. /NM3 becomes /NM1 for 1 hour duration

Dimensions: Length 310mm x Height 240mm x Depth 40mm

Cut out dimensions: Length 310mm x Height 60mm x Depth 35mm



Options Suffix:

/R Recessed Version






Savona



P54

Edge-lit exit sign
in single and
double-sided versions

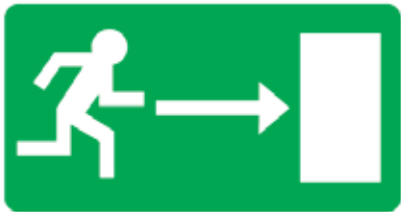

L16



L19



L17



L20



L22



L18



L21



L23