



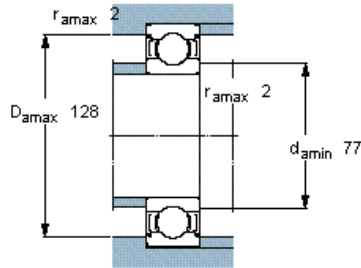

United... Products Bearings, units and ... Ball bearings Deep groove ball bearings SKF Energy Efficient (E2) deep groove ball bearings
Deep groove ball bearings, single row, SKF Energy Efficient (E2) bearings

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	B	dynamic C	static C ₀	Reference speed r/min		
mm			kN				-
65	140	33	93,6	60	11000	5300	E2.6313-2Z/C3

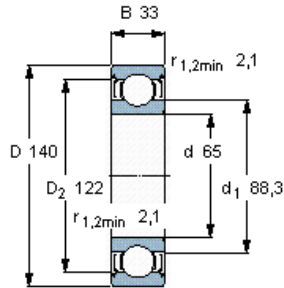

Calculation factors

k_r 0,03
f₀ 13