



SETRON, cylindrical fuse link, 14x51 mm, 8 A, gG, Un AC: 690 V

Figure similar


Model		
product brand name		SETRON
product designation		Cylindrical fuse link
General technical data		
operating class of the fuse link		gG
type of voltage of the operating voltage		AC
supply voltage at DC		250 V
Dissipation		
power loss [W]		1.4 W
power loss [W] for rated value of the current at AC in hot operating state per pole		1 W
Main circuit		
operational current rated value		8 A
Product details		
product component striker		No
Mechanical Design		
mounting position		Any, preferably vertical
net weight		21 g
Approvals Certificates		
General Product Approval		other
		Environment



[Confirmation](#)

[Environmental Confirmations](#)

Further information	
Information on the packaging	
https://support.industry.siemens.com/cs/ww/en/view/109813875	
Information- and Downloadcenter (Catalogs, Brochures,...)	
http://www.siemens.com/lowvoltage/catalogs	
Industry Mall (Online ordering system)	
https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW6108-1	
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)	
https://support.industry.siemens.com/cs/ww/en/ps/3NW6108-1	
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)	
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW6108-1	
CAx-Online-Generator	
http://www.siemens.com/cax	
Tender specifications	
http://www.siemens.com/specifications	

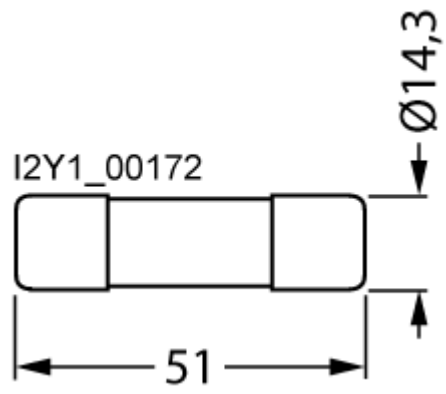

last modified:

4/11/2025 

