

Data Sheet

Interchangeable Multi-Purpose Machine Centre Sets



Suitable for steadying a range of both male and female component centres


Sets supplied with 1 live Centre and a selection of 7 different interchangeable male and female cone centre configurations.

Supplied in a wooden case together with an extractor tool

Set	7719161	7719164
Morse Taper	MT-2	MT-3
Max. Rotating Speed	5000 rpm	4300 rpm

Packed Weight and Dimensions

Code	Shank	Weight g	W mm	H mm	L mm
7719161	MT-2	1104	105	65	185
7719164	MT-3	1916	140	76	220

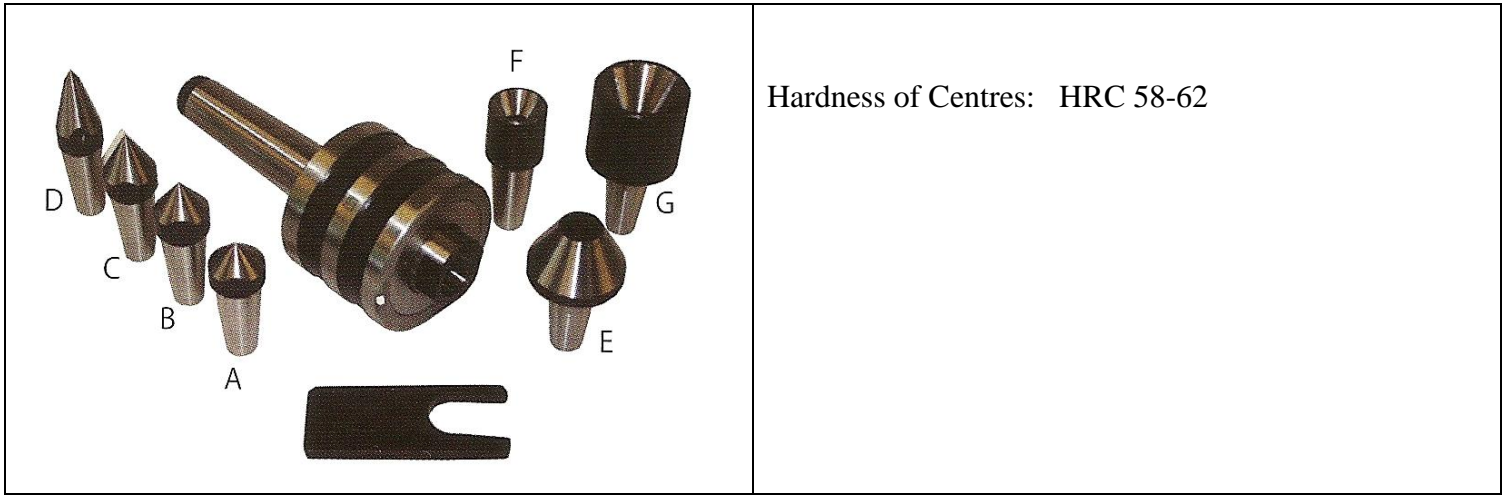

Interchangeable Centre Details

Centre	Type	Angle	Max. Dia. mm 771-9161	Min. Dia. mm 771-9161	Max. Dia. mm 771-9164	Min Dia. mm 771-9164
A	Male	90	15.0	0	18.0	0
B	Male	75	15.0	0	18.0	0
C	Male	60	15.0	0	18.0	0
D	Male	60	15.0	0	18.0	0
E	Male	60	23.0	10.5	34.0	17.0
F	Female	60	9.0	5.0	17.0	10.5
G	Female	60	15.0	7.0	28.0	16.0