


PCB Plugs  
1527260000

When good enough just isn't good enough

**Weidmüller** 

**BLZ 5.08, Screw Clamp: Clamping Yoke, 180°  
Orientation, Non-locking**

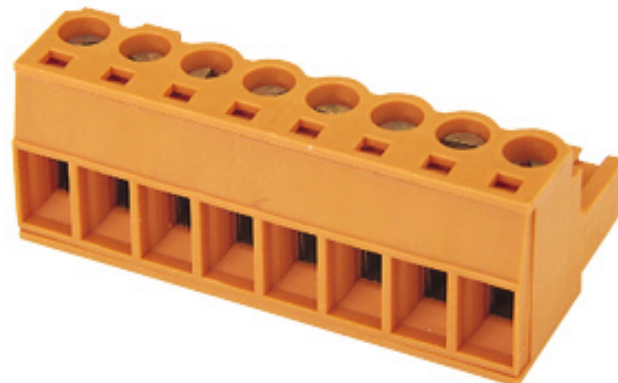

Representative Photo

**Technical Information**

Connector Options	Socket Block
Pitch	5.08 mm
Poles	10
Connection Method	Screw Clamp: Clamping Yoke
Orientation	180°
Locking	No
Color	Orange
Wire Size	#22...12 AWG
Rated Voltage UL	300 V
Rated Current UL	15 A
Configuration	Single row

**Technical Data**

	UL	CSA	VDE
Rated Voltage	300 V		
Rated Current	15 A		

**Additional Data**

**Suggested Accessories**

**Product Liability** The above information describes our products. It does not constitute guaranteed properties and is not intended to affirm the suitability of a product for a particular application. Regrettably, omissions and exceptions cannot be completely ruled out. Technical data are always specified by their average values. Exact data and the tolerances which apply to our processes can be requested from:

Weidmüller - North America  
United States 001 (800) 849-9343  
Canada 001 (800) 268-4080

or

Weidmüller - Germany  
Telephone operator 0049 (-5252) 960-0