

Features

- Multiple pins within a protective circular sheath and cables that plug into an interface to connect devices
- Enables a secure signal and current transmission
- Can be used in various applications to connect devices including, personal computers, audio and video to power, serial and data




Specification

Number of Poles	7
Current Rating	1 A
Voltage Rating	100 V
Contact Resistance	Pins 30 mOhm max., Shell 50 mOhm max.
Insulation Resistance	100 MOhm @ 500 VDC
Voltage Withstand	250 VAC RMS for 1 min.
Gender	Plug
Mating Type	Bayonet
Mounting Type	Cable Mount
Orientation	Straight
Termination Type	Solder Terminal

Material Specification

Strain Boot	PVC
Terminals	Brass, Silver Plated
Housing	PA66
Setscrew	Steel, Nickel Plated
"T" Holder	Steel, Nickel Plated
Screw Cap	Zn Alloy, Nickel Plated
Shield Cover	Zn Alloy, Nickel Plated

Drawing

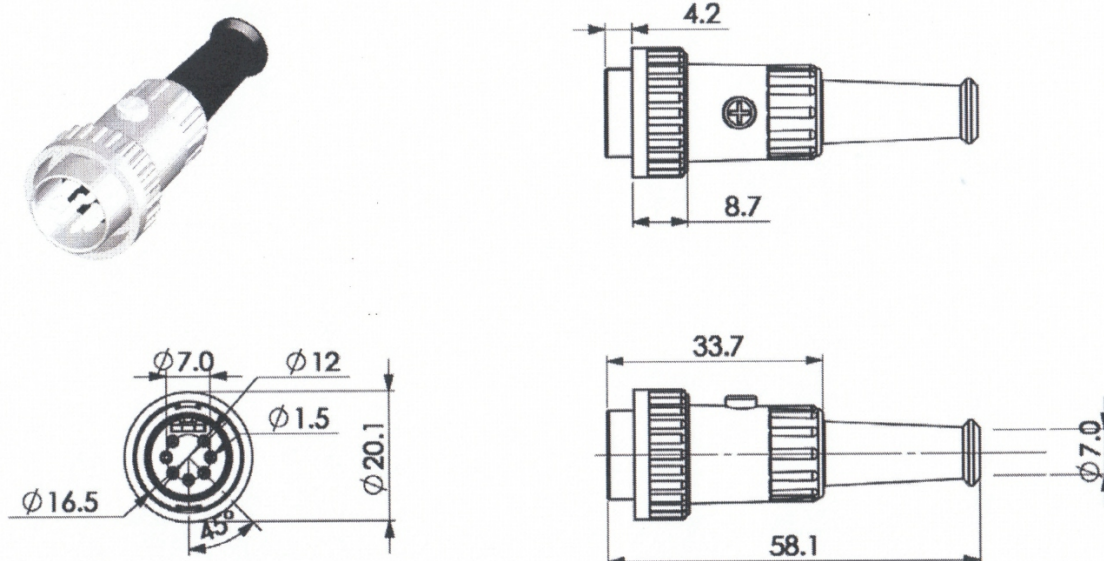

Art. Nr.
RND 205-01459