



**PowerCat C5e  
Keystone Jack**

**Features and Benefits**

The PowerCat C5e RJ45 Keystone Jack has been designed to be compatible with any products that accept the standard keystone profile. Suitable for high-speed data transmission, the PowerCat C5e Keystone Jack has been designed to comply with the requirements of TIA/EIA 568B.2, ISO/IEC 11801:2002, EN50173:2002 standards.

- Standard Keystone profile
- Dual colour coding allows 568A/B wiring configuration
- RJ11 compatible

**Compliant With**

TIA/EIA-568-B.2-1, FCC Subpart F 68.5, ISO 60603-7, ISO 11801:2002, EN 50173:2002

**Approvals**

- UL-1863 (Pending)
- CSA (Pending)

**Technical Information**

**Mechanical Characteristics**

**Jack Connector**

Plastic Housing: Polycarbonate, UL94V-0 rated or equivalent  
 Operating Life: Minimum 750 insertion cycles  
 Contact Material: Copper Alloy  
 Contact Plating: 1.25 micrometres Au/Ni  
 Contact Force: 100g minimum  
 Plug Retention Force: 5kg.


**IDC Connector**

Plastic Housing: Polycarbonate, UL94V-0 rated or equivalent  
 Operating Life: Minimum 20 reterminations  
 Contact Material: Copper Alloy  
 IDC Contact Plating: Tin/Lead Plate  
 Contact Force: 100g minimum  
 Wire Accommodation: 22-24 AWG solid

**Electrical Characteristics**

Interface Resistance: 20mΩ  
 Initial Contact Resistance: 2.5mΩ  
 Insulation Resistance: >100MΩ

Termination Tool: 110

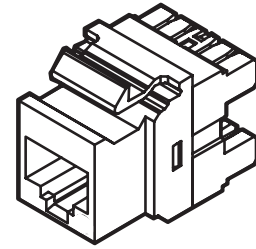

**Keystone Jack**  
 Dimensions:  
 23mm x 18mm x 30.6mm  
 Shipping Weight: 28g.

Keystone Jack C5e Performance (dB) Summary @ 100 MHz			
	Cat5E Spec.	Worst Case* Value	Worst Case Margin
Insertion Loss	-0.4	>-0.05	>0.3
NEXT	-43.0	-48.1	5.1
FEXT	-35.1	-45.1	10.0
Return Loss	-20.0	-35.8	15.8

\* = Worst value of all 4 pairs or pair combinations



Order No.	Description
KSJ-00032-**	Keystone Jack Category 5e 8W 568A/B

Insert colour code in place of \*\* in part number when ordering DataGate Plus jack or accessories:  
 10 = Almond, 02 = White, 04 = Black, 05 = Ivory, 08 = Light Grey, RD = Red, BL = Blue, GR = Green, YL = Yellow,  
 RG = Orange, PP = Purple

**MOLEX PREMISE NETWORKS**

**Molex Premise Networks  
Corporate Headquarters**  
 Tel: 603 324 0200  
 www.molexpn.com

**European  
Headquarters**  
 Tel: 44 (0) 1489 572111  
 www.molexpn.co.uk

**South Pacific  
Headquarters**  
 Tel: 61 3 9747 8322  
 www.molexpn.com.au

**Molex Incorporated**  
 Tel: 630 969 4550  
 www.molex.com