



Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)


EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUN 2020 (209) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Reflow solder capable to 245°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts




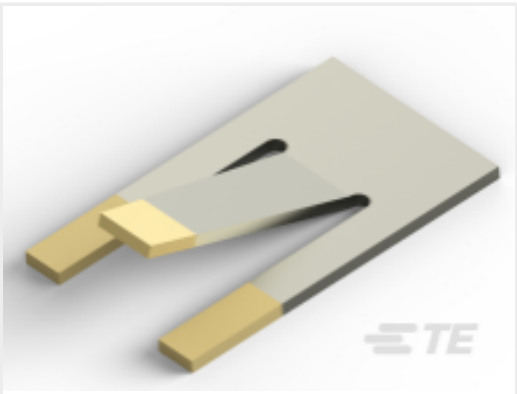

TE Part # 1447009-5
SHIELD FINGER 0820 TYPE



TE Part # 2199248-4
Shield Finger, Loose Piece, Type A, 1.0 h

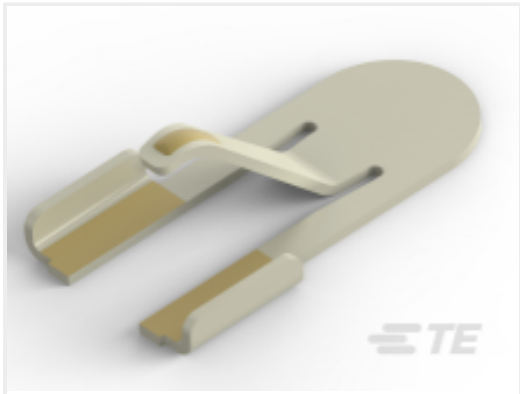

TE Part # 2199248-5
SHIELD FINGER, LOOSE PIECE, TYPE A, 1.3H



TE Part # 2336713-2
SPRING FINGER 1.45H



TE Part # 2040852-1
SHIELD FINGER 0820 N-B WITH SE



TE Part # 2306334-3
SPRING FINGER 1.2H



TE Part # 2306454-3
SPRING FINGER 2.3H



TE Part # 2306654-3
SPRING FINGER 1.8H



TE Part # 2199001-1
SHIELD FINGER 1210 EMBOSS PACKING

Customers Also Bought




TE Part #1-1462038-5
IM05NS=IM RELAY 140mW 9V




TE Part #1-1513472-5
UAM ASSEMBLY 270MM CABLE W /MHF4L CONN



TE Part #1-440052-5
2.5MM,HDR,15POS,VERTICAL, CONNECTOR

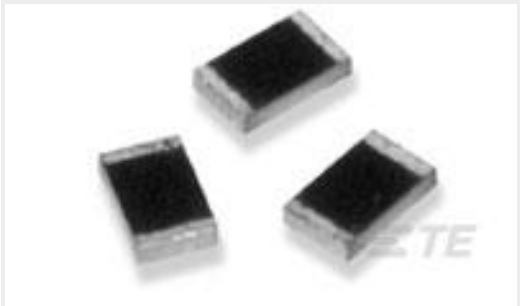

TE Part #4-1879273-9
RP 2A 768R 0.1% 15PPM CUT LENGTH

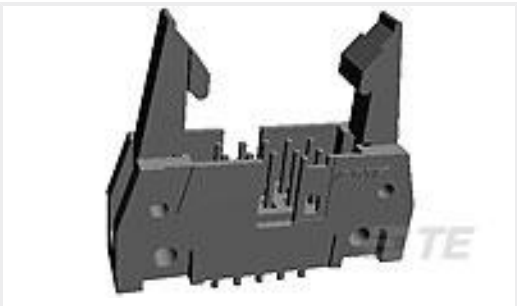

TE Part #5746443-9
A/L UNIV HDR 40P ACT PIN LAT



TE Part #3-1879337-4
CPF 0603 5K49 1% 50PPM 1K RL



TE Part #1-1825910-3
FSM8JLH=6MM TACT SWITCH, HIGH TEMP



TE Part #6-338311-2
25POS.HD20 PLUG ASS



TE Part #3-1879350-7
[RR01 5% 6R8 AMMO](#)



TE Part #2-1879462-9
[RL73H 2B R24 1% 1K RL](#)

Documents

Product Drawings

[WORLD GSM PCB ANTENNA TAPE AND REELED](#)

English

CAD Files

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_1513259-9_G.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1513259-9_G.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1513259-9_G.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[PCB ANTENNA](#)

English

Product Specifications

[Product Specification](#)

English