

# Wire Management

## VK-Flex Molded Nylon Wiring Duct (Halogen Free)

**Description:** A flexible wiring duct that is especially suitable for switchgear, control panels, distribution equipment, cubicles and other areas where flexibility of design and installation are required.

The one-piece design with its overlapping fingers, eliminates the separate cover used with conventional duct, makes rewiring easy and lends itself to a more efficient use of space. Open slots allow for lead-offs and because the duct is molded, there are no sharp edges.

Each strip is fully interlocking for continuous end-to-end attachment. Molded with slotted mounting holes, VK-FLEX is also available with a permanent, self-adhesive backing - eliminating the need for other types of fasteners.

The open design of VK-FLEX, allowing for air circulation along with a temperature operating range of -40°C to 100°C (-40°F to 212°F), makes it especially suitable for enclosed areas where heat build-up may be a problem.




### Specifications


**Material:** Polyamide UL94V-O

**Color:** Standard color is Gray

Mounting Slots Catalog Number	Permanent Self-Adhesive Strip Catalog Number	Dimensions						Wire Capacity			Std. Pkg. lengths
		(inches)			(mm)			#18	#16	#14	
		W	H	L	W	H	L				
VK-10 M5690	VK-10 L2212	0.43	0.59	9.84	11	15	250	10	8	5	40
VK-20 M5691	VK-20 L2222	0.90	0.83	19.68	23	21	500	20	18	13	40
VK-30 M5692	VK-30 L2232	1.30	1.22	19.68	33	31	500	57	46	30	40
VK-40 M5693	VK-40 L2242	1.69	1.77	19.68	43	45	500	101	81	53	40

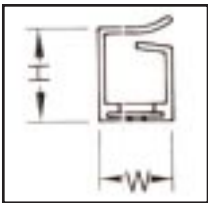

VK-10  
side view

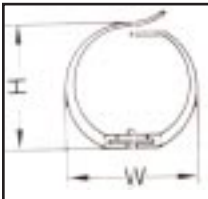

VK-20, 30 & 40  
side view

