


Product data sheet

Specifications

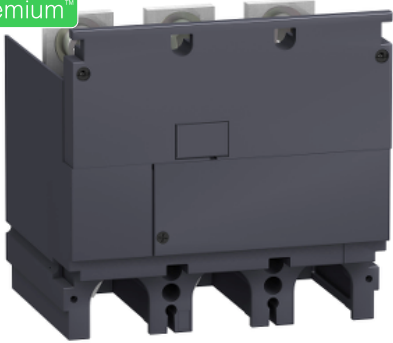

current transformer module with voltage output, ComPact NSX630, 600 A rating, 3 poles

LV432861

Main

Device short name	CT module and voltage output
Product or component type	Current transformer
Device application	Control
Range compatibility	ComPact NSX630
Poles description	3P
[In] rated current	600 A
Current transformer ratio	600/5 A
Power consumption in VA	2 VA
Accuracy class	Class 0.5

Complementary

[Ue] rated operational voltage	530 V
Network type	AC
Network frequency	50/60 Hz
Auxiliary connection terminal	Cable connector 2.5 mm ²

Environment

Electrical shock protection class	Class II
IP degree of protection	IP40 conforming to IEC 60529
IK degree of protection	IK04 conforming to IEC 62262

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	2.221 kg
Package 1 Height	13.0 cm
Package 1 width	17.0 cm
Package 1 Length	20.0 cm
Unit Type of Package 2	S03

Number of Units in Package 2	2
Package 2 Weight	4.929 kg
Package 2 Height	30.0 cm
Package 2 width	30.0 cm
Package 2 Length	40.0 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information

Contractual warranty

Warranty	18 months
-----------------	-----------