


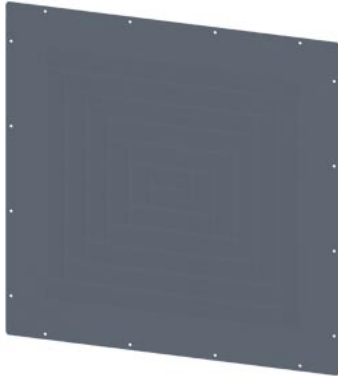

SIVACON, Roof, with Ventilation openings with Ventilation openings IP40, W: 800 mm, T: 800 mm, zinc-plated

| Model                                        |                           |                   |
|----------------------------------------------|---------------------------|-------------------|
| product brand name                           | SIVACON                   |                   |
| product designation                          | top plate                 |                   |
| design of the product                        | With ventilation openings |                   |
| design of the surface                        | zinc plated               |                   |
| design of the product EMC version            | No                        |                   |
| Protection class                             |                           |                   |
| protection class IP                          | IP40                      |                   |
| Suitability                                  |                           |                   |
| suitability for use for outside use          | No                        |                   |
| Product details                              |                           |                   |
| product component                            |                           |                   |
| • cable entry                                | No                        |                   |
| • ventilation                                | Yes                       |                   |
| Mechanical Design                            |                           |                   |
| width                                        | 800 mm                    |                   |
| depth                                        | 800 mm                    |                   |
| ventilation cross section outlet can be used | 860 cm²                   |                   |
| net weight                                   | 7.9 kg                    |                   |
| material                                     | steel                     |                   |
| Approvals Certificates                       |                           |                   |
| General Product Approval                     |                           | Test Certificates |
|                                              |                           | other             |



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other

Environment

[Miscellaneous](#)

Siemens  
EcoTech



[Environmental Confirmations](#)

### Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1088-2UD30-0A>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1088-2UD30-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=8MF1088-2UD30-0A](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1088-2UD30-0A)

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

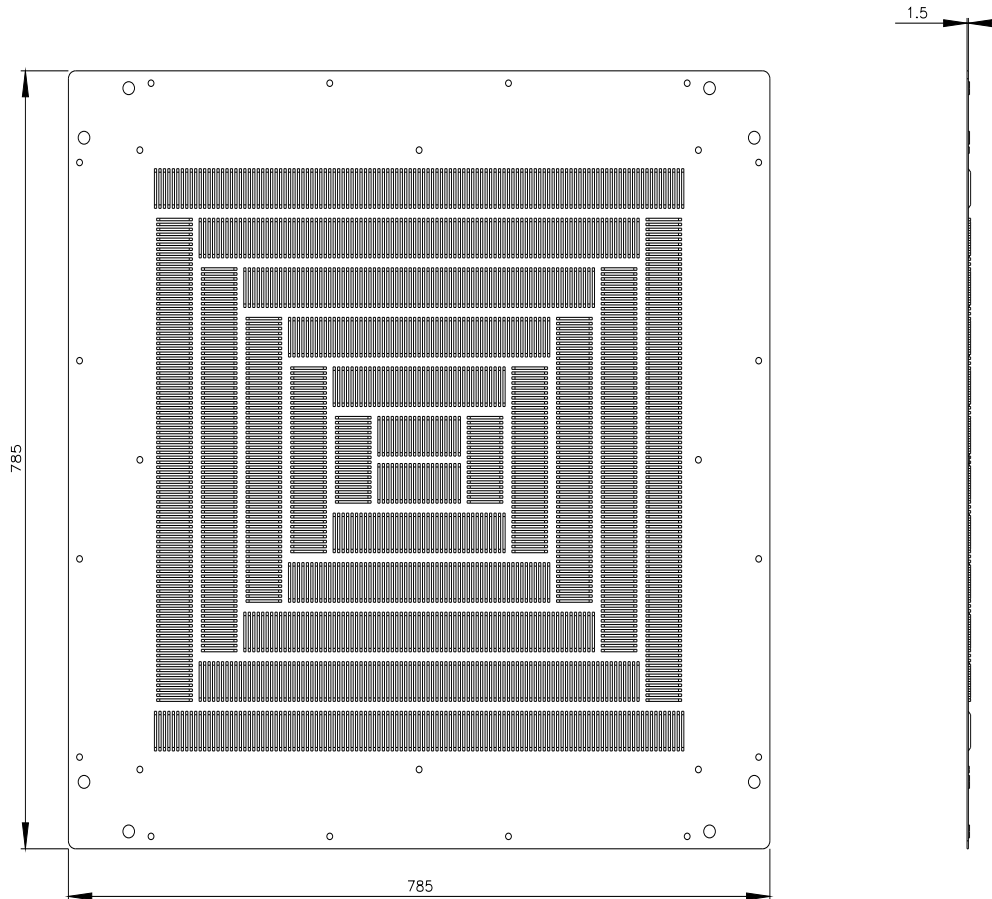

last modified:

1/16/2025 

