


PX0598/10/63 Datasheet

Product Name // IEC Connector Snap Fit To Panel C20
Inlet PX0598 Series 1mm Panel 6.3mm Tab Termination
EN60 320-1 Standard Sheet C20 Class I

 [View Product Page](#)



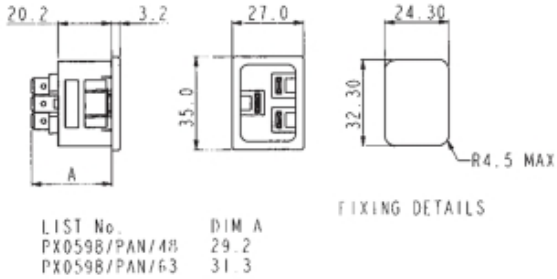

LIST No.	DIM A
PX0598/PAN/48	29.2
PX0598/PAN/63	31.3

// **Product Description:**



Snap Fit To Panel Mount C20 IEC Inlets



EN60 320-1 Standard Sheet C19 Class I and Standard Sheet C20 Class I



Cold Condition



Choice of panel thickness depending on part code: /10 - 1mm, /15 - 1.5mm, /20 - 2mm, /30 - 3mm



Choice of Termination depending on part code: /48 - 4.8mm Tab, /63 - 6.3mm Tab



Insulation Boot for rear of connector available separately (part code 14064)



Mate with PX0599

// **General Information:**

Product Display Title:

Product Family:

Product Series:

Approvals:

Body Material:

Current Max:

Flamability Rating:

Function:

Iec Connector Mates With:

Iec En60620 Type:

Max Operating Temperature:

Min Operating Temperature:

Max Panel Thickness:

Min Panel Thickness:

Number Of Contacts:

Voltage Max:

Snap Fit To Panel Mount C20 IEC Inlets

IEC Connectors

IEC60320 Main Inlets and Outlets

CSA, ENEC, UL, VDE

Nylon 66

16A, 20A

UL94V-0

Panel Mount Connector

PX0599

EN60 320-1 Standard Sheet C20 Class I

+70°C

-40°C

1mm

1mm

3 Contacts

250V

// **Product PDF Links**



[IEC Connectors product data](#)

// **Product 3D CAD Model Links**



[PX0598/10/633D CAD Model](#)

// **Product Certificate Links**



[VDE Certificate](#)



[UL Certificate](#)