

Features

- Tempered glass window
- Range 0 – 1 MPa / 0 – 150 psi
- Analogue display

Integrated Gauge 0 – 1 MPa / 0 – 150 psi

RS Stock No.: 0767779,
0767782, 0767780, 0767783



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

Standard pneumatic / air gauge.

Black enamelled steel case.

Push fit plastic window.

Brass/bronze wetted parts.

Accuracy $\pm 2.5\%$ of full range.

For the measurement of fluid liquids that are not:- highly viscous, high temperature (over 60°C), likely to solidify/crystallize or corrosive to copper or tin alloys.

Compatibility

Round gauge	0767779	0767782	0767780	0767783
Connection	Back	Back	Back	Back
Thread	PT 1/8"	PT 1/8"	PT 1/8"	PT 1/4"
pressure	0-0.4MPa/60 PSI	0-10 Bar	0-1MPa/150 PSI	0-1MPa/150 PSI
Dial Dia	40mm	40mm	40mm	40mm
Compatible with RS Part Numbers	2351138 2351135 2351137	2351106 2351139	2351135 2351137 2351138	2351107, 2351109 2351145

General Specifications

Mounting Type	Back Entry
Display type	Analogue
Series	EPR
Case Material	Steel
Window Material	Plastic window





Mechanical Specifications

Working Pressure	75% of FSV for static pressure; 66% of FSV for pulsating pressure
Connection Size	Integrated
Gauge Outside Diameter	See drawings
Minimum Operating Temperature	0°C
Maximum Operating Temperature	+60°C
Calibrated	No

Technical Specifications and Drawings

0767779

0767782

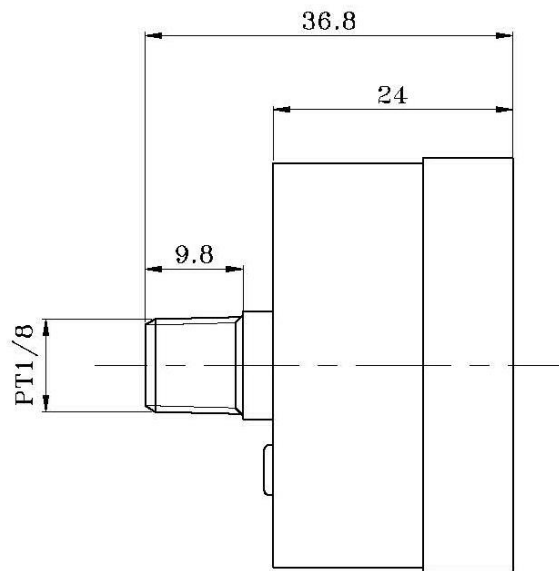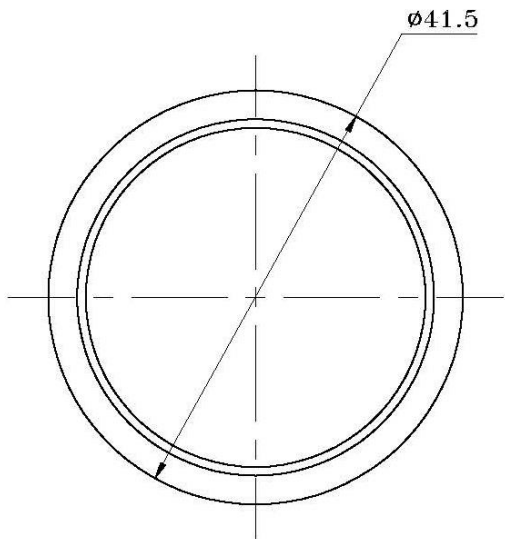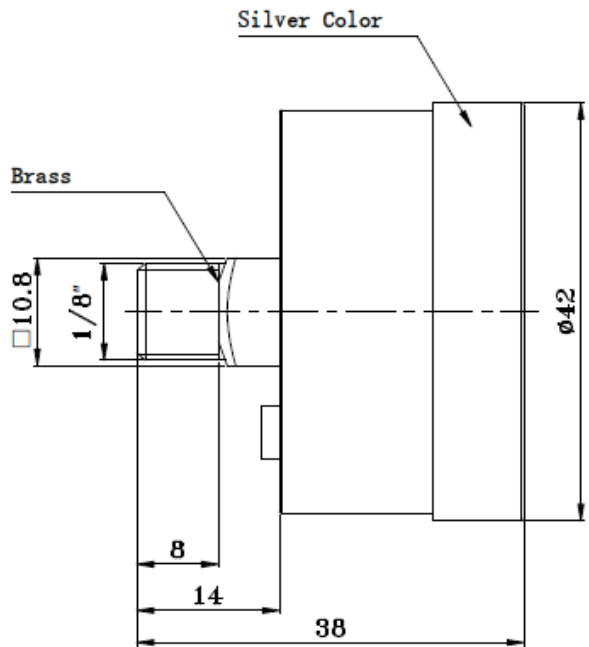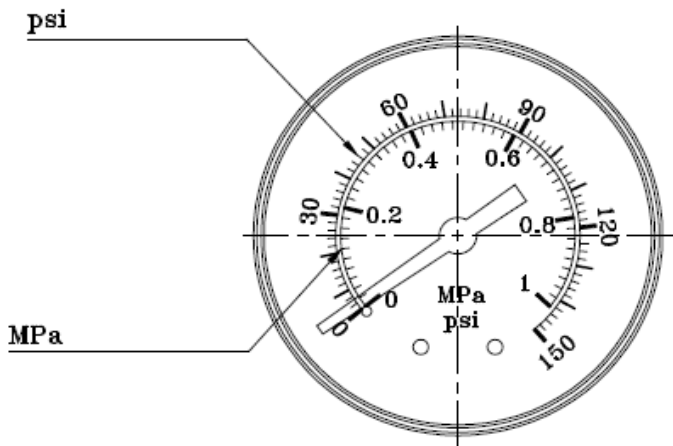

0767783

