




ENGLISH

Datasheet

RS Pro Magnetic Illuminated Pickup Tool

RS Stock No: 394-150

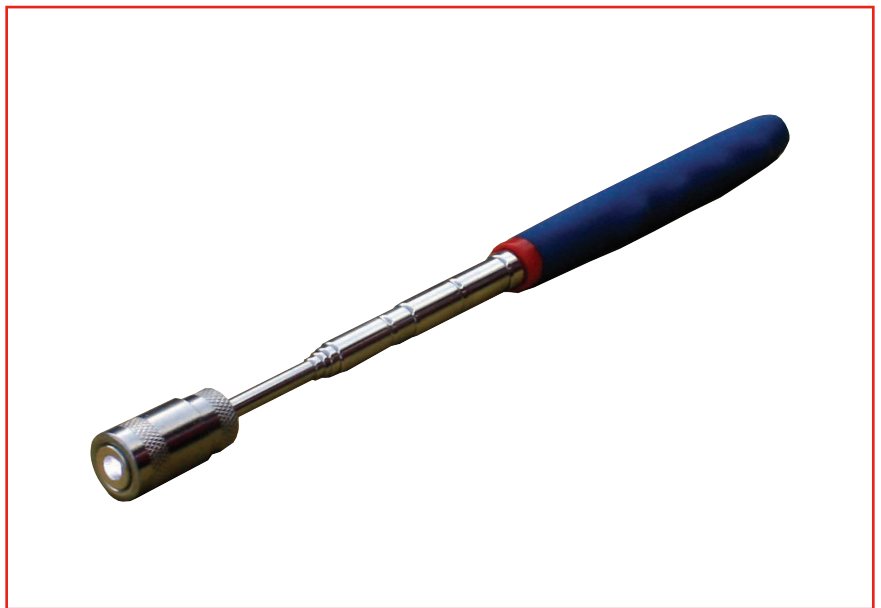

Specifications:

Bright LED Light through magnet centre giving 360 degree illumination

Overall length fully retracted: 190mm / 7 1/2"

Overall length fully extended: 810mm / 32"

Magnetic Head diameter: 18mm / 0.7"

Magnet will lift: 1.5 kilo / 3.3 lbs

Non slip Soft Grip Moulded Handle, suitable for use with oily or wet hands


Packaging: Single unit supplied in blister pack complete with batteries

Order Code	Manufacturers Code	Description
394-150	PM-2	Magnetic Illuminated Pickup Tool

Datasheet

RS Pro Magnetic Illuminated Pickup Tool

RS Stock No: 394-150

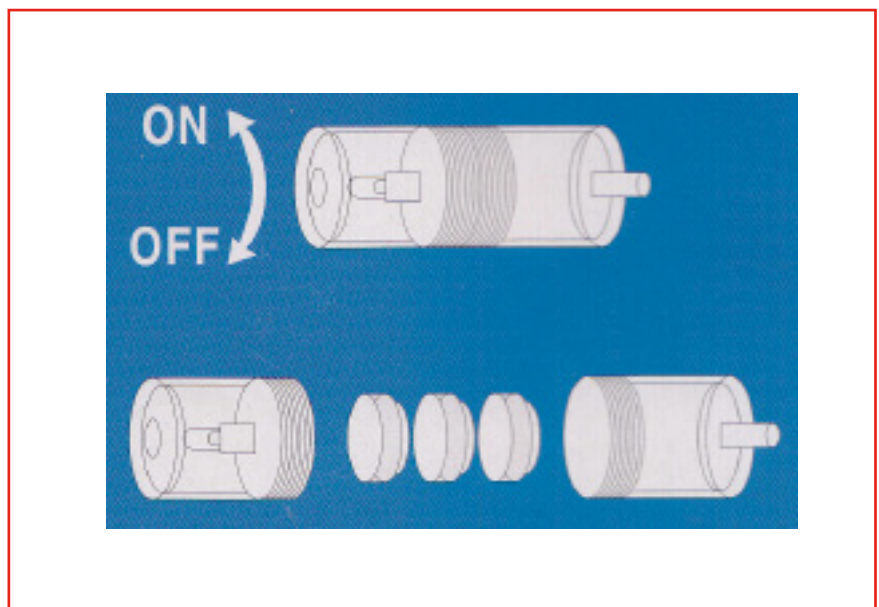

Operation:

Rotate magnetic head clockwise to switch on illumination, rotate anti-clockwise to turn off.

Battery replacement:

Rotate magnetic head fully anti-clockwise to for access to batteries. Remove plastic battery holder and remove the 3 batteries.

Replace with 3 x SR44/1.5v Alkaline cells

Ensure that all cells are inserted with + sign towards the LED lamp contact.

Reassemble the magnetic head

Order Code	Manufacturers Code	Description
394-150	PM-2	Magnetic Illuminated Pickup Tool