



Sledge hammer spanner, 7444SG-M

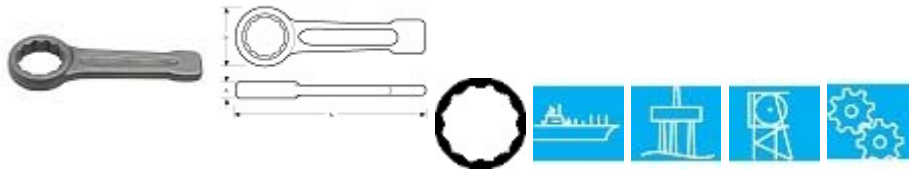
Ring-end sledge hammer spanner.






DIN 7444

Finish: steel grey.

Material: SPECIAL STEEL, forged.

Short and strong profiled handle and striking end for heavy duty operations in shipyards, railways, heavy industries, etc.



					L mm	A mm	B mm 
7444SG-M-27		1829834	1	27	180	16	46 295
7444SG-M-30		1829841	1	30	190	17	52 400
7444SG-M-32		1829858	1	32	190	17	52 400
7444SG-M-34		1838560	1	34	205	18	57 400
7444SG-M-36		1829865	1	36	205	18	58 540
7444SG-M-41		1829872	1	41	230	20	66 700
7444SG-M-42		1829889	1	42	230	20	66 700
7444SG-M-46		1829896	1	46	240	22	74 970
7444SG-M-50		1829919	1	50	255	24	80 1130
7444SG-M-55		1829926	1	55	270	25	86 1345
7444SG-M-60		1829933	1	60	280	26	93 1650
7444SG-M-65		1829940	1	65	300	30	102 2000
7444SG-M-70		1829957	1	70	330	33	110 2600
7444SG-M-75		1829964	1	75	330	33	110 2600
7444SG-M-80		1829971	1	80	360	36	126 3500
7444SG-M-85		1829988	1	85	360	36	126 3500
7444SG-M-90		1829995	1	90	390	40	142 5000
7444SG-M-95		1830007	1	95	390	40	142 5000
7444SG-M-100		1830014	1	100	420	45	155 6500
7444SG-M-105		1830021	1	105	420	45	155 6500
7444SG-M-110		1830038	1	110	450	48	170 7800

7444SG-M-115	1830045	1	115	450	48	170 7800
7444SG-M-120	1830052	1	120	480	54	182 9400
7444SG-M-125	1830069	1	125	480	54	182 8500
7444SG-M-130	1830076	1	130	520	58	202 13000
7444SG-M-135	1830083	1	135	520	58	202 11900
7444SG-M-140	1830090	1	140	520	58	202 12500
7444SG-M-145	1830106	1	145	580	64	228 18500
7444SG-M-150	1830113	1	150	580	64	228 18750
7444SG-M-155	1830120	1	155	580	64	228 18550
7444SG-M-160	0132508	1	160	580	64	228 18000
7444SG-M-165	0132515	1	165	650	70	565 25000
7444SG-M-170	0132522	1	170	650	70	565 25000
7444SG-M-175	0132539	1	175	650	70	565 25000