

0 601 066 J00 – GCL 2-15 G

Material number	0 601 066 J00
EAN	3165140869553
Retail price	233.33 GBP
Discount Group	GDM
Origin product ID BI	40034.0
Baretool number	3601K66J00
1/2 L-BOXX inlay for tool 1 608 M00 C1S	✓
3 x battery 1.5 V LR6 AA	✓
Laser target plate	✓
RM 1 Professional 0 601 092 600	✓



Technical data


Description

Applications


Drywall installation
Levelling work
Suspended ceiling installation
Tiling
Interior fitting work
Point transfer

Technical data

Laser diode	Line: 500 – 540 nm, < 10 mW Point: 630 – 650, < 1 mW
Operating temperature	-10 – 50 °C
Storage temperature	-20 – 70 °C
Laser class	2
Working range	15 m
Accuracy	± 0.3 mm/m
Working range of laser points, max.	10 m (top) 10 m (bottom)
Self-levelling range	± 4°
Levelling time	4 s
Dust and splash protection	IP 54
Power supply	3 x 1.5 V LR6 (AA)
Operating time (max.)	6 h in cross line and point mode 8 h in cross line mode 10 h in line and point mode 12 h in line mode 22 h in point mode
Tripod thread	1/4", 5/8"
Weight, approx.	0.49 kg
Colour of laser line	green
Projection	2 lines / 2 points
Plumb point accuracy	± 0.7 mm/m

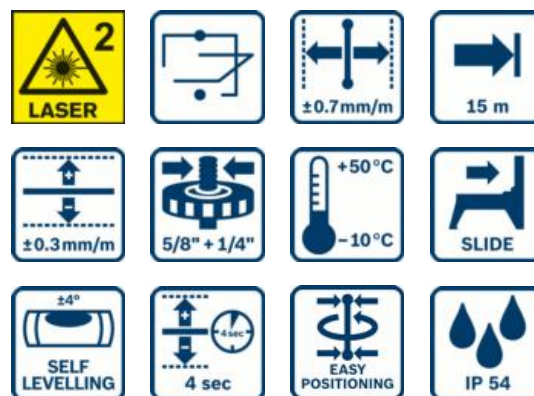

GREENLASER Technology

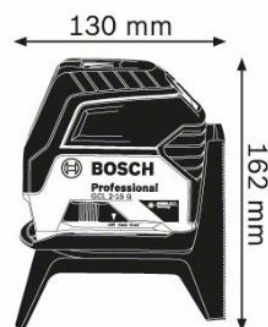

Sales information

Positioning

- Four times better visibility thanks to green laser lines

User benefit

- Green horizontal and vertical lines for maximal visibility
- Multifunctional rotating mount for easy alignment of the laser lines around the plumb points
- Red plumb points for precise transfer application

Other features

- Pendulum lock ensures safe transport
- Easy handling due to single-handed operation and intuitive user interface
- Line and point mode freely selectable
- Horizontal and vertical self-levelling up to $\pm 4^\circ$