



Figure similar

SITOR cylindrical fuse link, 14x51 mm, 20 A, gR, Un AC: 690 V, Un DC: 600 V

Model	
product brand name	SETRON
product designation	SITOR cylindrical fuse link
General technical data	
operating class of the fuse link	gR
type of voltage of the operating voltage	AC
supply voltage at DC	600 V
Main circuit	
operational current rated value	20 A
Product details	
product component striker	No
Mechanical Design	
mounting position	Any, preferably vertical
net weight	23 g
Approvals Certificates	
General Product Approval	other



[Confirmation](#)


other	Environment
-------	-------------

[Miscellaneous](#)

[Environmental Con-
firmations](#)

[Environmental Con-
firmations](#)

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875
Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/lowvoltage/catalogs
Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NC1420-0MK
Service&Support (Manuals, Certificates, Characteristics, FAQs,...) https://support.industry.siemens.com/cs/ww/en/ps/3NC1420-0MK
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...) http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NC1420-0MK
CAX-Online-Generator

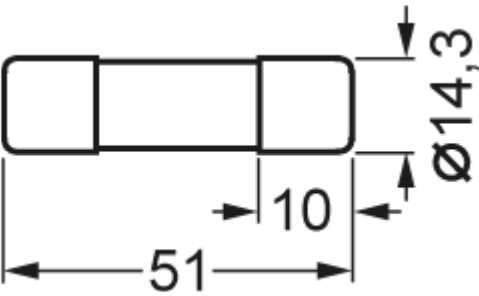

last modified:

4/11/2025

