

MESS- UND REGELTECHNIK MESURE ET RÉGLAGE




info@rothcoag.ch
www.rothcoag.ch

ROTH+CO. AG

Wiesentalstrasse 20
CH-9242 Oberuzwil

Tel. 071 955 02 02
Fax 071 955 02 00

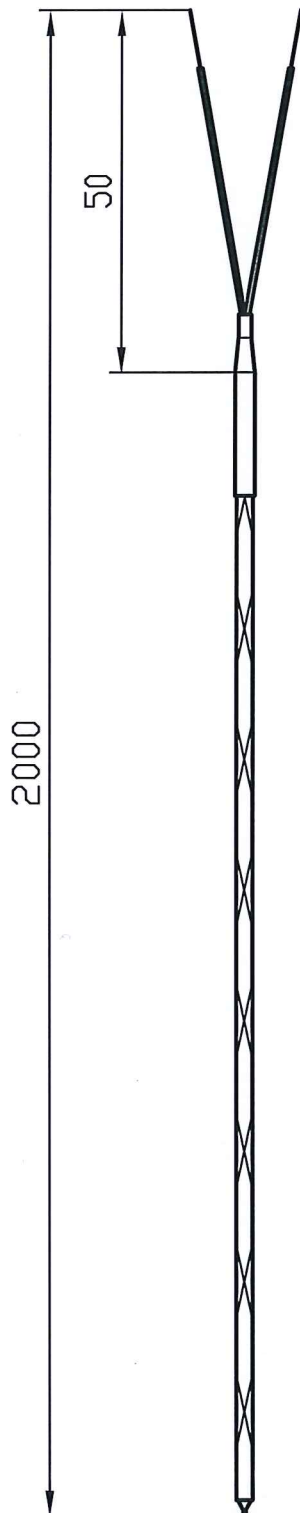

Thermoelement Thermocouple Thermocouple

Artikel Nummer
Numéro d'article
Order number

**T010.0.50.1J.02000.-
055.4.U**

Thermoelement Typ
Thermocouple type
Thermocouple type

J

Klasse
Classe
Class

1

Toleranz
Tolérance -40...+375 °C
Tolerançe

1,5 °C oder
1,5 °C ou
1,5 °C or
0,004 x [t]
0,004 x [t]
0,004 x [t]

Messstelle
Point de mesure
Hot junction

unisoliert
non isolé
uninsulated

Thermoleitung
Câble thermocouple
Thermocouple cable

D= 2 x 0,50 mm

Isolation
Isolation
Insulation

Glasseide
soie de verre
Fibreglass

Aussenmantel
Manteau extérieur
Outer jacket

Glasseide
soie de verre
Fibreglass

Aussenabmessung
Dimension extérieur
Outside dimension

oval, 1,2 x 2,3 mm

Norm
Norme
Code

DIN EN 60584-3

Max. Temperatur
Température max.
Max. Temperature

+400 °C

100288 T010 1x Typ ✓