


Deep groove ball bearings, single row, shield on both sides

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
10	26	8	4,75	1,96	0,083	67000	34000	0,019	6000-2Z *

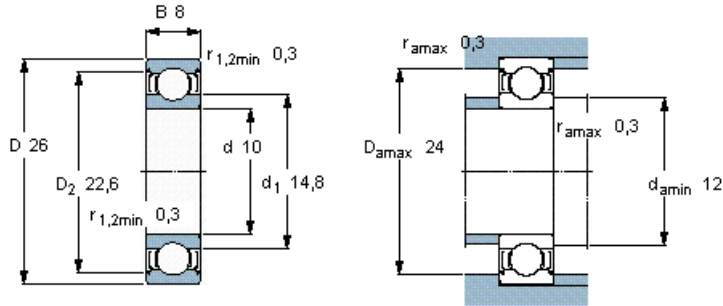

Calculation factors

$k_r = 0,025$
 $f_0 = 12$