

SITOR CYLINDRICAL FUSE LINK AR 32 A, 600 V
AC/400V DC



Figure similar

| Model | | |
|--|---|----------|
| product brand name | | SENTRON |
| General technical data | | |
| Size of the fuse link | | 10x38 mm |
| Main circuit | | |
| Operating voltage / Rated value | V | 690 |
| Operating current / Rated value | A | 32 |
| Product details | | |
| Product component / striker | | No |
| Net weight | g | 10 |
| Equipment marking | | |
| <ul style="list-style-type: none"> • acc. to DIN EN 61346-2 • acc. to DIN EN 81346-2 | | F F |

General Product Approval

Declaration of Conformity



Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/3NC1032>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/3NC1032/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NC1032

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://ausschreibungstexte.siemens.com/tiplv>

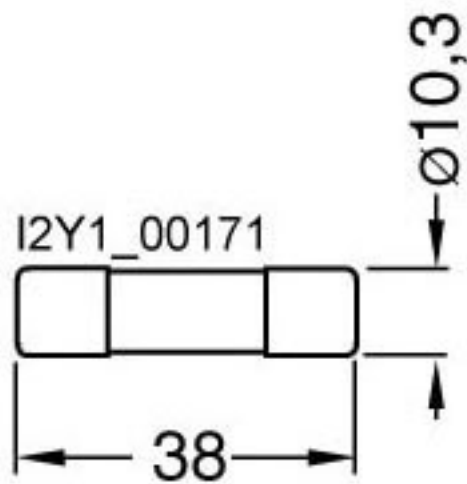

last modified:

27.04.2015