

Oblique Cutting Pliers



DESCRIPTION:

Oblique tip cutters for professionals, thin jaws and slim head

Special pliers made from high grade special steel for extremely high requirements

By precision inductiv hardness process blades achieve up to 65 HRC

Box joint - double leaf spring

Precise jaw adjustment without backlash

High gloss steel polished surface


Ergonomically formed bicoloured hand guard - dissipative anti-slide material

The pliers have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas

SPECIFICATION:

Length	130 mm
A - Head width	11 mm
B - Head length	20 mm
C - Head thickness	6.5 mm
G - Blade / jaw length	5 mm
Cutting edge bevel	Fine - Flush cut
Cutting capacity soft wire	Ø 0.8 mm
Cutting capacity medium wire	Ø 0.6 mm
Cutting capacity hard wire	-
Weight	64 g

Art. Nr.
RND 550-00259

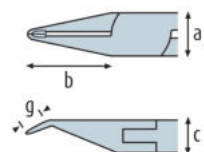

a=11mm/.433"
b=20mm/.788"
c=6.5mm/.256"
g=5mm/.197"