


- Hublot 75 W
- Wandlicht 75 W

- 75 W bulkhead
- Leuchte 75 W

- Hublot 75 W
- Fanale 75 W

604 76 / 77

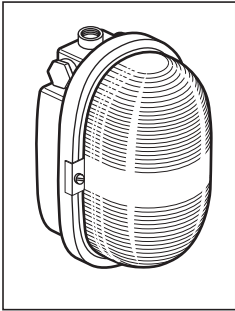


- Installation
- Installatie
- Installation
- Installation
- Instalación
- Instalazione

- L'installation doit être réalisée conformément à la norme en vigueur.
Amplitude aux chocs thermiques 110° C
- De installatie moet uitgevoerd worden overeenkomstig geldende normen.
Amplitude bij thermische schokken van 110° C
- The installation must be done in accordance with applicable standard.
Heat shock resistance amplitude 110° C
- Montage und Anschluß müssen entsprechend den gültigen Vorschriften durchgeführt werden.
Temperaturwechselfestigkeitsspanne 110° C
- Debe realizarse conforme a la norma en vigor.
Rango máximo de temperatura 110° C
- L'installazione deve essere realizzata conformemente alla norma in vigore.
Escursione agli shock termici 110° C



- Fixation
- Bevestiging
- Fixing
- Befestigung
- Fijación
- Fissaggio

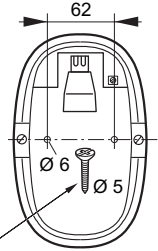


- non fournie
- niet bijgeleverd
- not supplied
- nicht mitgeliefert
- no abastecido
- non fornita

- Raccordement
- Aansluiting

- Connection
- Anschluß

- Conexiones
- Collegamento

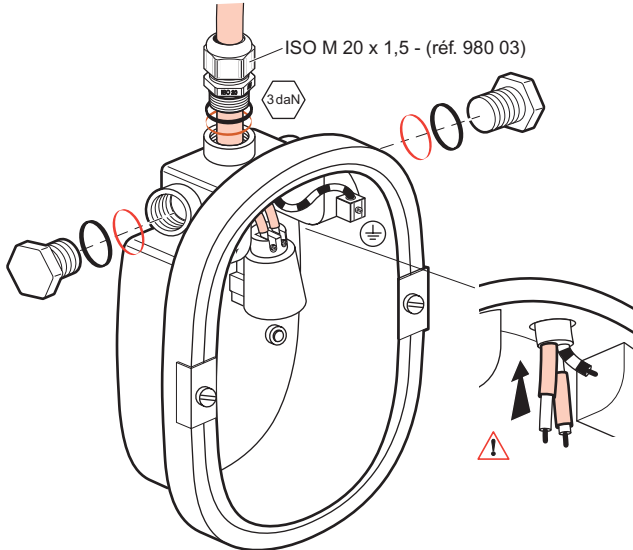

	B 22	E 27
	60 W maxi	75 W maxi
	75 W maxi	75 W maxi
	75 W maxi	75 W maxi

- Accessoire
- Toebehoren
- Accessory
- Zubehör
- Accesorio
- Accessorio



- Grille de protection réf. 605 08
- Rooster
- Protective grill
- Schutzgitter
- Rejilla de protección
- Griglia di protezione