 


RGBW

Diffused On Board Tape



Key Features:

- CRI ≥ 80
- High lumen output
- Fitted with 3M adhesive tape
- Continuous diffused LED, no spotting
- Supplied with 5M reels
- DALI/KNX/ZIGBEE/DMX/BLE Bluetooth/RF compatible

DOB SPECIFICATION


Part Code	DOB-896-RGBSW-XX	DOB-896-RGBWW-XX	DOB-896-RGBNW-XX	DOB-896-RGBCW-XX
Voltage	24VDC			
Power Consumption	16W/m			
LED Qty	896			
LED Pitch	1.12 mm			
Lumen Output	Red 80lm/m	Green: 220lm/m	Blue: 40lm/m	White: 280lm/m
CCT	2500K	3000K	4000K	6000K
CRI	80Ra			
Cut Points	62.5mm			
IP Rating	IP20/IP67			
Back Adhesive	3M			
Working Temperature	-20°C ~ +40°C			
Width Dimensions	5000/12mm (IP20)	5000/14mm (IP67)		

LED Flexi Strip width & IP rating part codes
12mm width ~ IP20 = 20 14mm Width ~ IP67 = 67 i.e.: DOB-896-RGBW-20




Mechanical Diagrams

IP20 Diagram

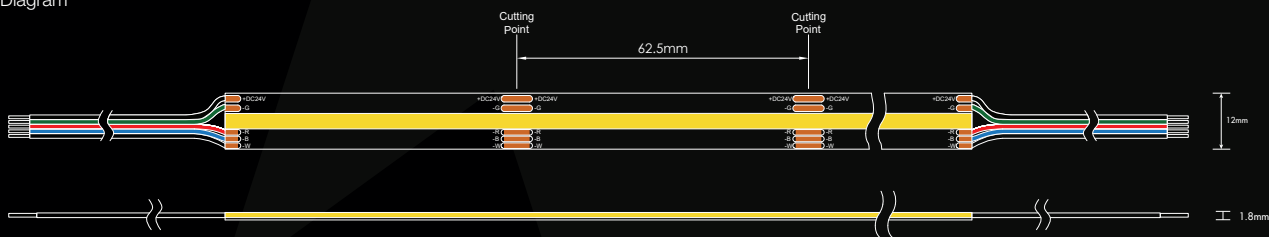

IP67 Diagram

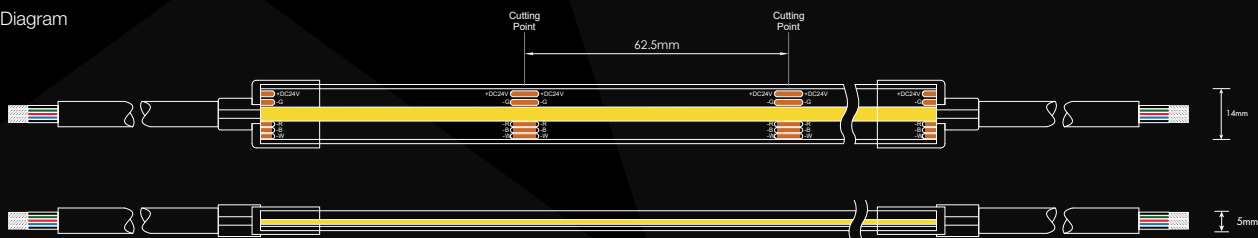

PowerLed
Orion House
Calleva Park
Aldermaston
Berkshire
RG7 8SN

Contact:
0118 9703856
enquiries@powerled.uk.com
www.powerled.uk.com

