



Product Features

- Suitable for security & general outdoor lighting applications
- Industrial design embedding user convenience and flexibility
- High-level for ease of installation & low maintenance fit and forget applications
- 50,000 hr life time
- Proven provider of switchmode power supplies to support in-house LED driver technology
- Designed to provide applications long product life cycle and high energy saving capabilities
- 36 months warranty for approved installations

LED FLOODLIGHTING

FLEX 10W Floodlights

Model	• FLEX-10C	• FLEX-10W
Lumen Output (lm)	≥700	≥700
Input Voltage	85-265VAC 47/63Hz	85-265VAC 47/63Hz
Power Consumption (W)	10W	10W
Efficiency (lm/W)	≥70	≥70
Power Factor	≥0.98	≥0.98
CRI (Ra)	70	70
Dimensions (LxWxDmm)	178 x 169 x 50	178 x 169 x 50
Weights (kg)	1.15	1.15
Angle (°)	120	120
IP	IP65	IP65
CCT (K)	6000-7000K	2900-3200K

FLEX 30W Floodlights

Model	• FLEX-30C	• FLEX-30W
Lumen Output (lm)	≥2,400	≥2,400
Input Voltage	85-265VAC 47/63Hz	85-265VAC 47/63Hz
Power Consumption (W)	30W	30W
Efficiency (lm/W)	≥77	≥77
Power Factor	≥0.98	≥0.98
CRI (Ra)	80	80
Dimensions (LxWxDmm)	294 x 240 x 80	294 x 240 x 80
Weights (kg)	2.0	2.0
Angle (°)	120	120
IP	IP65	IP65
CCT (K)	6000-7000K	2900-3200K

FLEX 50W Floodlights

Model	• FLEX-50C	• FLEX-50W
Lumen Output (lm)	≥3,500	≥3,500
Input Voltage	85-265VAC 47/63Hz	85-265VAC 47/63Hz
Power Consumption (W)	50W	50W
Efficiency (lm/W)	≥70	≥70
Power Factor	≥0.98	≥0.98
CRI (Ra)	80	80
Dimensions (LxWxDmm)	358 x 332 x 100	358 x 332 x 100
Weights (kg)	3.4	3.4
Angle (°)	120	120
IP	IP65	IP65
CCT (K)	6000-7000K	2900-3200K

FLEX 80W Floodlights

Model	• FLEX-80C	• FLEX-80W
Lumen Output (lm)	≥6,160	≥6,160
Input Voltage	85-265VAC 47/63Hz	85-265VAC 47/63Hz
Power Consumption (W)	80W	80W
Efficiency (lm/W)	≥77	≥77
Power Factor	≥0.92	≥0.92
CRI (Ra)	80	80
Dimensions (LxWxDmm)	421 x 383 x 126	421 x 383 x 126
Weights (kg)	8.0	8.0
Angle (°)	120	120
IP	IP65	IP65
CCT (K)	6000-7000K	2900-3200K

FLEX 100W Floodlights


Model	• FLEX-100C	• FLEX-100W
Lumen Output (lm)	≥7,700	≥7,700
Input Voltage	85-265VAC 47/63Hz	85-265VAC 47/63Hz
Power Consumption (W)	100W	100W
Efficiency (lm/W)	≥77	≥77
Power Factor	≥0.98	≥0.98
CRI (Ra)	80	80
Dimensions (LxWxDmm)	421 x 383 x 126	421 x 383 x 126
Weights (kg)	8.0	8.0
Angle (°)	120	120
IP	IP65	IP65
CCT (K)	6000-7000K	2900-3200K

FLEX 120W Floodlights


Model	• FLEX-120C	• FLEX-120W
Lumen Output (lm)	≥9,240	≥9,240
Input Voltage	85-265VAC 47/63Hz	85-265VAC 47/63Hz
Power Consumption (W)	120W	120W
Efficiency (lm/W)	≥77	≥77
Power Factor	≥0.98	≥0.98
CRI (Ra)	80	80
Dimensions (LxWxDmm)	421 x 383 x 126	421 x 383 x 126
Weights (kg)	8.0	8.0
Angle (°)	120	120
IP	IP65	IP65
CCT (K)	6000-7000K	2900-3200K

LED FLOODLIGHTING


FLEX 10W Floodlights

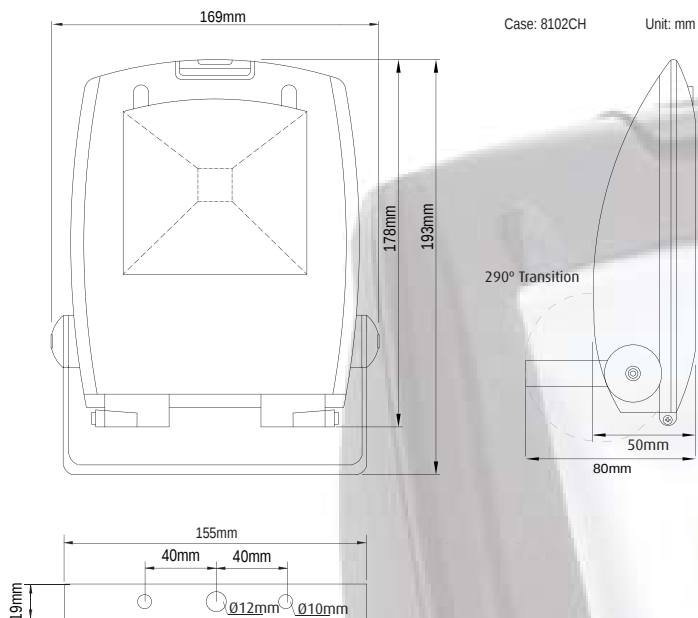

FLEX 30W Floodlights

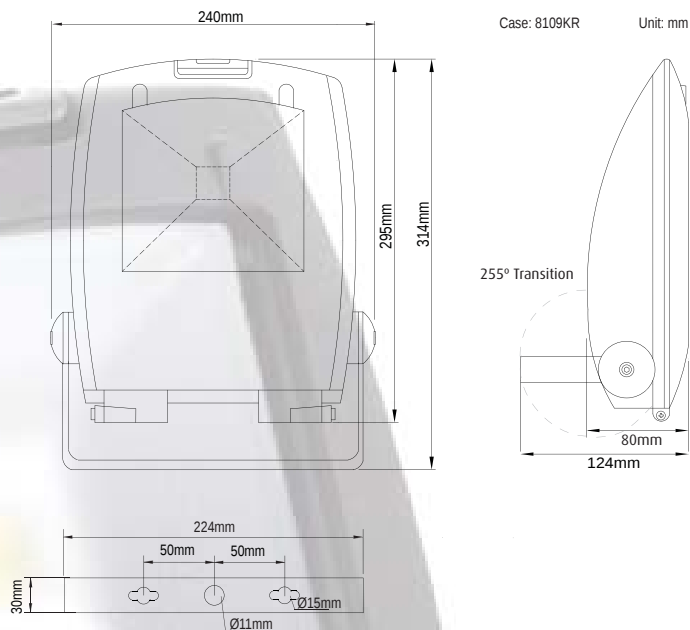

FLEX 50W Floodlights

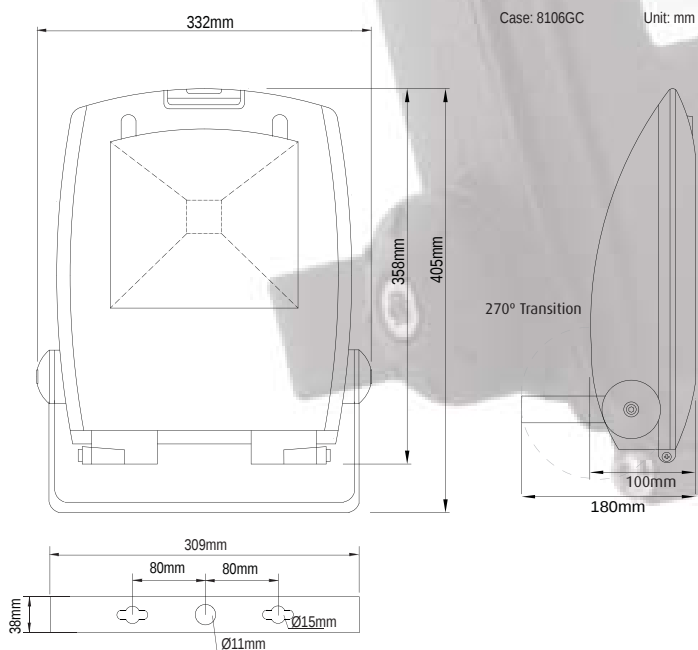

FLEX 80W & FLEX 100W & FLEX 120W Floodlights

