

## PCB-Adapter Han DD 1.6mm (LCP)

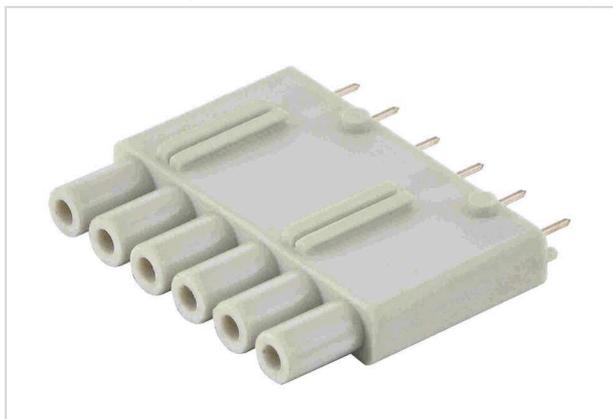


Image is for illustration purposes only. Please refer to product description.

Part number	09 16 000 9996
Specification	PCB-Adapter Han DD 1.6mm (LCP)
HARTING eCatalogue	<a href="https://harting.com/09160009996">https://harting.com/09160009996</a>

### Identification

Category	Accessories
Type of accessory	PCB adapter
Description of the accessory	In the Han DD <sup>®</sup> crimp insert
	In the Han DD <sup>®</sup> module
	In the Han <sup>®</sup> DDD module (different electrical data: 7.5 A 160 V 2.5 kV 3)

### Version

Gender	Male
	Female
Details	for PCB's up to 1.6 mm

### Technical characteristics

Rated current	7.5 A
Rated voltage	250 V
Rated impulse voltage	4 kV
Pollution degree	3
Limiting temperature	-40 ... +125 °C

### Material properties

Material (insert)	Liquid crystal polymer (LCP)
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained



**Pushing Performance**  
Since 1945

## Material properties

REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

## Commercial data

Packaging size	10
Net weight	3.044 g
Country of origin	Romania
European customs tariff number	85366990
GTIN	5713140190672
eCl@ss	27460201 PCB connector (board connector)
ETIM	EC002637
UNSPSC 24.0	39121415