


212A.35 212A - Dead-blow hammers, interchangeable tips

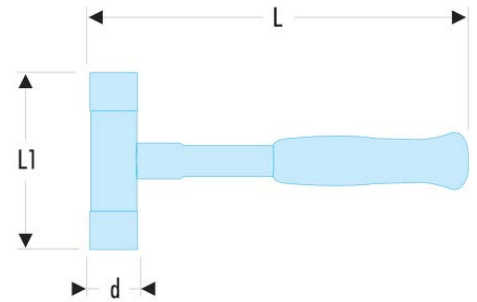

- Glass fiber handle.
- Steel body.
- Easily replaceable, special nylon tips shore hardness D74 ± 5.
- Ergonomic PVC grip.
- Presentation: black epoxy.
- Spare tip: 212.E35 to E60.

d [mm]: 35

L [mm]: 305

L1 [mm]: 112

[kg]: 0,698