

Features

- HDMI F-F
- Length: 15cm
- Colour: Black

RS PRO 0.15m High Speed with Ethernet HDMI Stub F-F

RS Stock No. 0839389



RS Professionally Approved Products bring to you, professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

HDMI stub for use with faceplates, HDMI v1.4 which is now called HDMI High Speed with Ethernet as version numbers can no longer be used on cables. The stub comes with two mounting screws.

General Specifications


Connector 1	HDMI (Panel Mount)
Connector 1 Gender	Female
Connector 2	HDMI
Connector 2 Gender	Female
Length	15cm
Colour	Black
HDMI Version	High Speed with Ethernet

Approvals

Standards Met	CE UKCA ROHS REACH
---------------	--------------------

Similar Products


Stock No.	Brand	Product Name
0839389	RS PRO	0.15m High Speed with Ethernet HDMI Stub F-F
0839390	RS PRO	0.16m High Speed with Ethernet HDMI Stub M-F

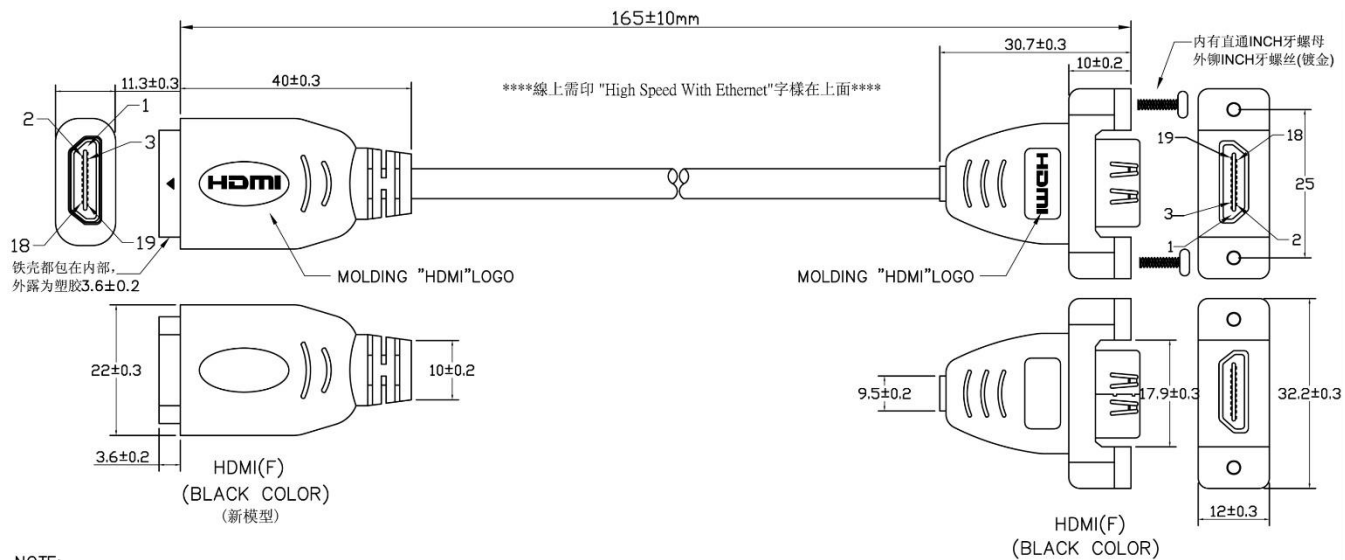

NOTE:

1. CABLE: 28AWG, UL20276, AL+B-FOIL, [(#28*1P+AL)*5PCS+ #28*4C+D]+AM+B, BLACK COLOR, OD=7.3±0.2mm, PVC JACKET
2. LENGTH: 165MM.
3. CONNECTORS: HDMI19P(F)*2PCS (BLACK INSULATOR) (镀金头).
镀金INCH牙螺丝*2PCS, 镀金直通INCH牙螺母*2PCS.
4. MOLD: MOLDING TYPE.
5. CONTACTS:

HDMI(F)	1	3	2	4	6	5	7	9	8	10	12	11	14	19	17	13	15	16	18	64
HDMI(F)	1	3	2	4	6	5	7	9	8	10	12	11	14	19	17	13	15	16	18	64
	PAIR		G	PAIR		G	PAIR		G	PAIR		G	PAIR		G	28AWG				SHELL
6. Test machine test condition.
 - A. 100% OPEN, SHORT & INTERMITTANCE TEST.
 - B. CONDUCTOR RESISTANCE: 3ohms MAX.
 - C. INSULATION RESISTANCE: 5M Min./10ms.
7. ALL MUST BE MEET ON ROHS COMPLIANT.

 

螺丝*2PCS



直通螺母*2PCS