


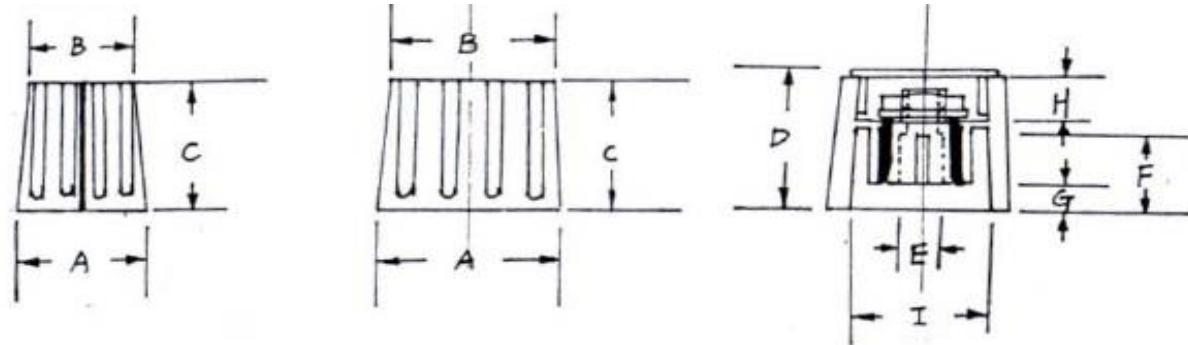

TOLERANCE : $\pm 0.20\text{mm}$

Collet Knob




RS Stock_No	PART No	A	B	C	D	E	F	G	H	I	LINE
463-8520	CF-BH15-S(3.2) / B	14.7	13.0	16.2	17.0	3.2	6.7	0.0	7.3	10.0	WITHOUT LINE
463-8485	CF-BH15-S(6) / B	14.7	13.0	16.2	17.0	6.0	6.7	0.0	7.3	10.0	WITHOUT LINE
463-8508	CF-BH21-S(6) / B	21.3	19.6	17.1	18.1	6.0	10.0	3.2	5.0	17.0	WITHOUT LINE
463-8514	CF-BH15L-S(6) / B	14.7	13.0	16.2	17.0	6.0	6.7	0.0	7.3	10.0	WITH LINE
463-8457	CF-BH15-S(6.4) / B	14.7	13.0	16.2	17.0	6.4	6.7	0.0	7.3	10.0	WITHOUT LINE
463-8463	CF-BH21-S(6.4) / B	21.3	19.6	17.1	18.1	6.4	10.0	3.2	5.0	17.0	WITHOUT LINE
463-8479	CF-BH15L-S(6.4) / B	14.7	13.0	16.2	17.0	6.4	6.7	0.0	7.3	10.0	WITH LINE

CAP




RS Stock_No	PART No	Cap size
463-8536	CF-BH15-6 / C	14.7
463-8542	CF-BH21-6 / C	21

4638536

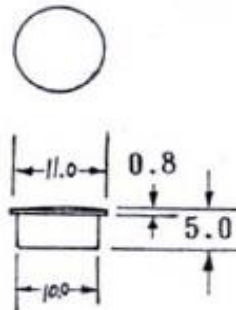

4638542

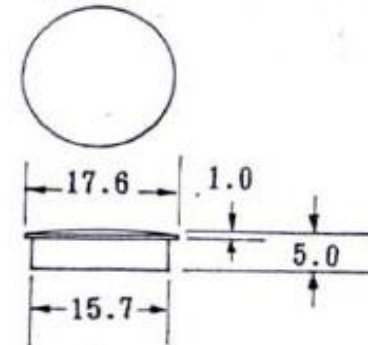





Nut cover



RS Stock_No	PART No	cover size
463-8564	CF-BH15 / NC6	14.7
463-8570	CF-BH15L / NC6	14.7

4638570

4638564

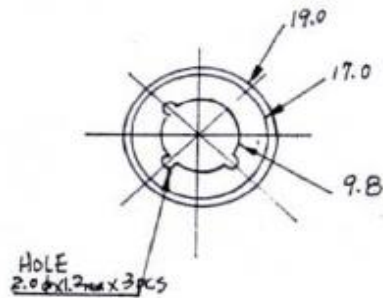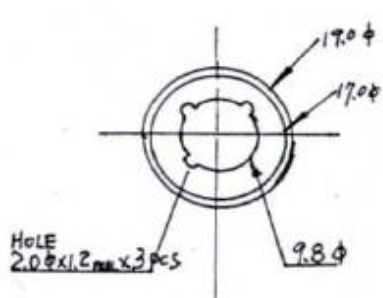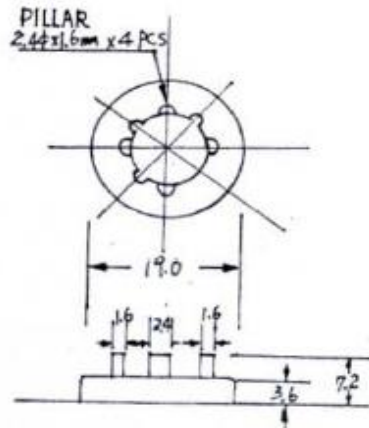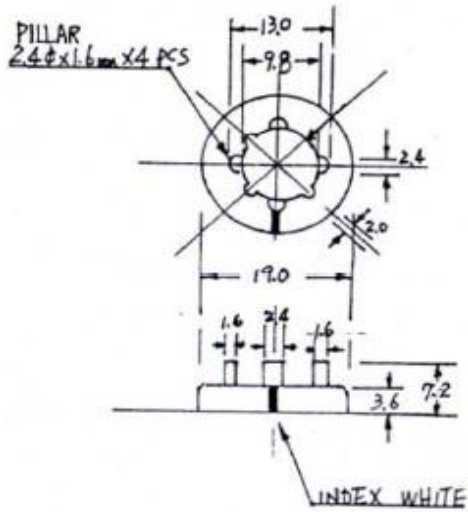

Knob pointer



RS Stock_No	PART No	pointer size
463-8586	CF-BH15 / R6	14.7
463-8592	CF-BH21 / R6	21

4638592

4638586

