



Visit the website for your country to get more information and discover our products.

India ▾

[Proceed](#)

HellermannTyton

09/07/2026

Cable tie mount for edge, T=10.0 - 12.0mm, black, 96pcs.

Art.-No. 156-03633 | HDEC10-12-PRE-PA6GF30/C75S-BK |

[Copy item description](#)



- PFAS-free metal clamp for environmentally conscious applications
- Supports up to three cable ties for secure multi-cable bundling
- Compatible with five panel thicknesses: 6–8 mm, 8–10 mm, 10–12 mm, 12–14 mm, and 14–16 mm
- Assembly using adjustable pliers (e.g. water pump or channel lock pliers)
- EdgeClip pre-positioned before compression, minimizing surface damage during installation
-

[Show more](#) ▾





Visit the website for your country to get more information and discover our products.

[Proceed](#)

HellermannTyton

09/07/2026

Heavy Duty EdgeClip

Base Data

Application	The new Heavy Duty EdgeClips are specifically designed for high-load applications in challenging environments such as truck manufacturing, wind energy systems, and industrial installations including steel construction and structural beams. Installation can be carried out using either a dead blow hammer or, for the HDEC-Pre versions, water pump or channel lock pliers, offering flexibility on-site. The design allows for parallel routing of up to three cables and lines, supporting organized and efficient cable management even under demanding conditions.
Colour	Black (BK)
Fixation Method	Edge Clip
Material	Polyamide 6, glass-fibre reinforced (PA6GF30), Steel C75S (C75S)
PART DESCRIPTION	HDEC10-12-PRE-PA6GF30/C75S-BK
N	
Package Content	96 pcs.
Package Content packed in	box
Product Family	HDEC-Series for heavy duty applications
Product Group	Heavy Duty EdgeClip
Short Description	Robust, PFAS-free Heavy Duty EdgeClip: up to 3 cable bundles, easy edge mounting (10–12 mm) using pipe or water pump pliers.
Type	HDEC10-12-PRE
Variant	Edge Clip
Weight/Unit	0.022703 kg



Visit the website for your country to get more information and discover our products.

Proceed



09/07/2026

Length (L)	10.0 mm
Panel Thickness	10.0 - 12.0 mm
Width (W)	33.0 mm
for Panel Thickness	10 - 12 mm
s min - max	

Specifications

ELV compliant (Article 4 - 2)	Yes
Halogen-free	Yes
Hazardous Goods	No
Operating Temperature	-40 °C to +120 °C, (+150 °C, 5000h; +160 °C, 3000h; 180 °C, 100h)
PFAS-free	Yes
ROHS compliant	Yes
Reusable (Yes/No)	No
Specifications	HF ✓ RoHS ✓





Visit the website for your country to get more information and discover our products.

[Proceed](#)

HellermannTyton

09/07/2026

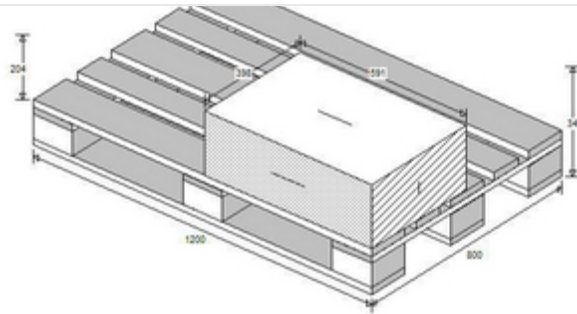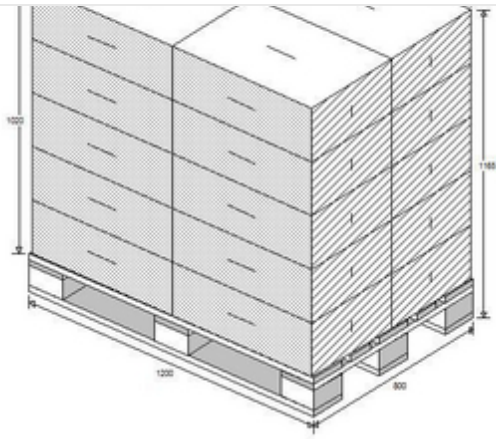

Country of Origin	PL
Customs Number	39269097
GTIN-13 / EAN	4031026759890
Packaging 1 - Height (m)	0.17 m
Packaging 1 - Length (m)	0.288 m
Packaging 1 - Qty	96
Packaging 1 - Type	box
Packaging 1 - Volume (m ³)	0.00871488 m ³
Packaging 1 - Weight (kg)	2.29928 kg
Packaging 1 - Width (m)	0.178 m
Packaging 3 - Height (m)	0.204 m
Packaging 3 - Length (m)	0.591 m
Packaging 3 - Qty	384
Packaging 3 - Type	box

 Visit the website for your country to get more information and discover our products.

[Proceed](#)



09/07/2026

Packaging 3 - Width	0.598 m
h (m)	
Packaging 4 - Height	1.204 m
ht (m)	
Packaging 4 - Length	1.2 m
th (m)	
Packaging 4 - Qty	7680
Packaging 4 - Type	pallet
Packaging 4 - Volume	1.156 m ³
me (m ³)	
Packaging 4 - Weight	225.279 kg
ght (kg)	
Packaging 4 - Width	0.8 m
h (m)	

More Information

ETIM 7.0 Key	EC000449
ETIM 8.0 Key	EC000449
ETIM 9.0 Key	EC000449
UNSPSC Key	39121717



 [International](#)



Visit the website for your country to get more information and discover our products.

[Proceed](#)

HellermannTyton

09/07/2026

[Contact](#)

[Terms of Service](#)

[Guidelines and Commitments](#)

[Social Media](#)

© HellermannTyton 2026 (v4.311.8) | [Update: 27/06/2026](#) | [Privacy Settings](#)
