



RF Connectors

↳ **BNC Connectors**

greenpar 1-1337457-0 -- 1 of 1 products

(Tyco Electronics P/N: 1-1337457-0)


Searchable Features:

Brand:	Greenpar
Government/Industry Qualification:	No
Product Type:	Adapter
Body Style:	Straight
Surface Mount:	No
Grade:	Professional
Connector Impedance:	50
Panel Attachment:	No
Center Contact Material:	Brass
Center Contact Plating:	Silver
Body Material:	Brass
Body Plating:	Silver
Adapter Type:	Jack - Jack
Sealed:	No
Isolated:	No
Dielectric Material:	PTFE
Packaging Method:	Individual
Polarized:	No

Other Properties:

Military Style Number:	UG-914/U
Packaging Quantity:	50
Operating Temperature (Max.) (°C):	165
Frequency:	DC to 4 GHz

LOC	DIST	REVISIONS					
E	B	P	LTR	DESCRIPTION	DATE	DWN	APVD
		A		RELEASE FOR PRODUCTION	07-SEP-00	RS	RG

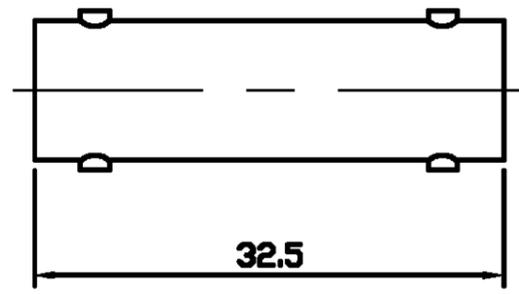

ALL DIMENSIONS ARE NOMINAL AND ARE TO BE USED FOR REFERENCE ONLY.

BAG	SINGLE ITEM	1-1337457-0
PACK TYPE	DESCRIPTION	PART NUMBER

HANDTOOL PART NUMBER	N/A
FOR USE ON CABLES	N/A
CONNECTOR PLATING DETAIL	SILVER
CONTACT PLATING DETAIL	SILVER
DIELECTRIC MATERIAL	TEFLON
GASKET MATERIAL	N/A

THIS DRAWING IS A CONTROLLED DOCUMENT.	
DIMENSIONS: MM	TOLERANCES UNLESS OTHERWISE SPECIFIED:
	0 PLC ± 0.5 1 PLC ± 0.5 2 PLC ± 0.5 3 PLC ± - 4 PLC ± - ANGLES ± - ± 0.5
MATERIAL	FINISH
-	-

DWN R.SMITH 07-SEP-00	Tyco Electronics Corporation Stanmore, Middlesex, HA7 4RS
CHK R.GOODALL 07-SEP-00	
APVD R.GOODALL 07-SEP-00	
PRODUCT SPEC 108-3435	
APPLICATION SPEC	NAME BNC STRAIGHT ADAPTOR J-J 50 Ohm
WEIGHT	SIZE A3
CUSTOMER DRAWING	CAGE CODE 00779
	DRAWING NO C-1337457
	RESTRICTED TO
	SCALE NTS
	SHEET 1 OF 1
	REV A