

## Features

- Made of Stainless Steel
- Panel to tongue depth of 26 mm
- IP54

## RS PRO Silver Stainless Steel Cabinet Lock, 26 mm Panel to Tongue, Key Unlock

RS Stock No: 192-9647



RS PRO Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description


Need to keep sensitive documents or valuables safe? This RS PRO cabinet lock is designed just for that. You'll find it used in residential and commercial settings, from boatyards and gyms to offices and factories.

It's simple to fit, as you just need to mount the cam lock onto the front of your door to create a secure locking system. You can use it in damp and dirty environments too, because it's IP54 (International Protection) rated for protection against dust and water splashes.

This component works with a double-bit key, which is available separately. The lock has a cylinder body and a flat rotating arm that can be installed onto panels up to 26 mm in thickness. This means it's suited to thinner doors such as those found on electrical cabinets, lockers and furniture.

General Specifications

Panel To Tongue Depth	26mm
Material	Stainless Steel
Action	90° cam action lock
IP Rating	IP54

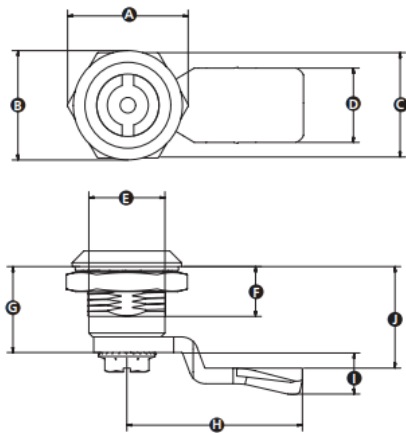

Part no.	A	B	C	D	E	F	G	H	I	J	Key type
1929647	31	28	27	19	20	13	22	45	11	26	Double bit key