


Fiche technique produit

LBBR 25

Roulement linéaire sans joints

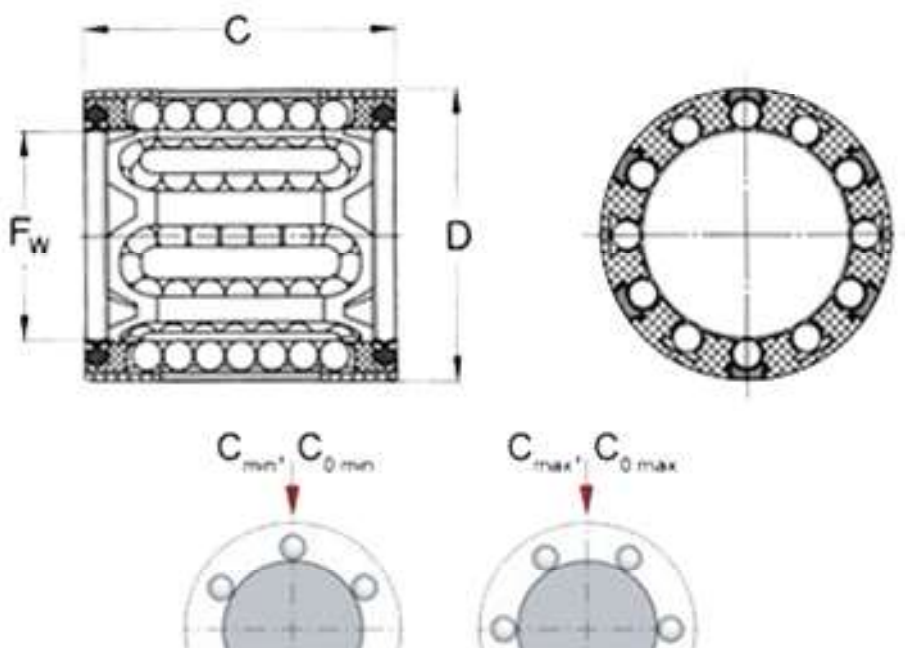

C [mm]:	40
D = Da [mm]:	35
Fw [mm]:	25
Rangées de billes [#]:	7

Date 13/05/2020

The contents of this report are the copyright of the publisher and may not be reproduced (even extracts) unless permission is granted. Every care has been taken to ensure the accuracy of the information contained in this report but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.

Fiche technique produit

LBBR 25

Roulement linéaire sans joints

Cdyn [N]:	2120
C0 [N]:	1560
Masse [kg]:	0.047

Date 13/05/2020

The contents of this report are the copyright of the publisher and may not be reproduced (even extracts) unless permission is granted. Every care has been taken to ensure the accuracy of the information contained in this report but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.