


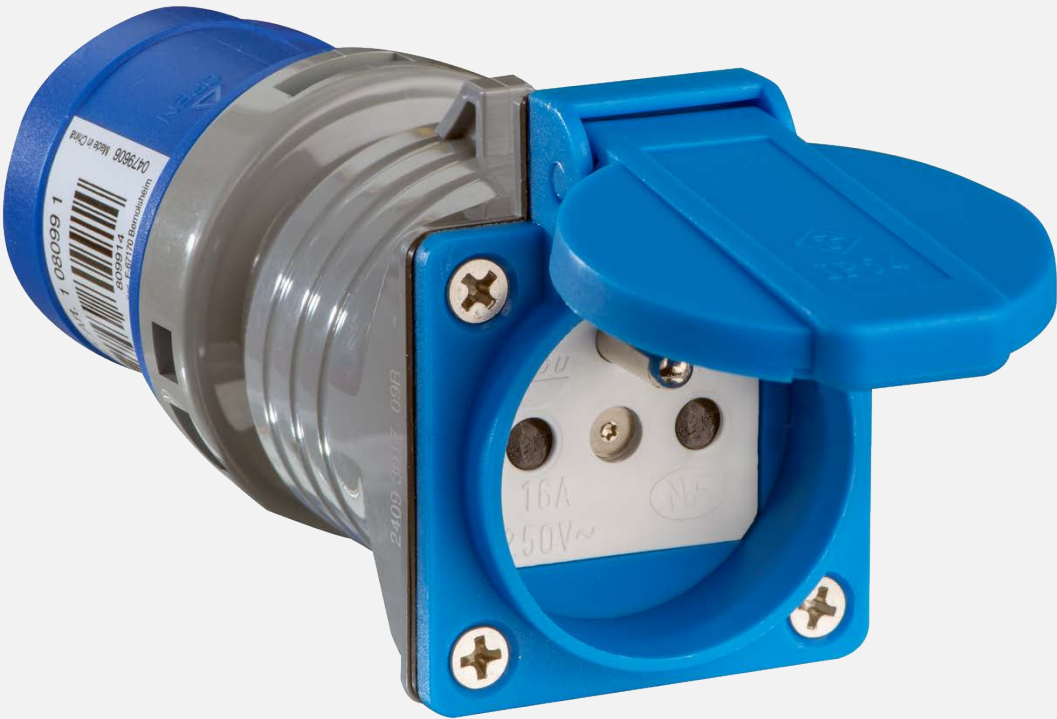

2 YEARS
MANUFACTURER
GUARANTEE

Product number

1080991

EAN

3281850809914

TECHNICAL DATA

Clock hour position	6 h	Nominal input voltage	250 V
Number of poles	3	Degree of protection (IP)	IP54
Max. current carrying capacity	16 A		

PACKAGING, DIMENSIONS AND WEIGHTS

UP	1	Weight of product (including packaging)	0.18 kg
Weight of product (without packaging)	0.17 kg	Dimension LxWxH (incl. packing)	5.2 cm x 6.7 cm x 12 cm
Dimension LxWxH (without packing)	5.2 cm x 6.7 cm x 12 cm		