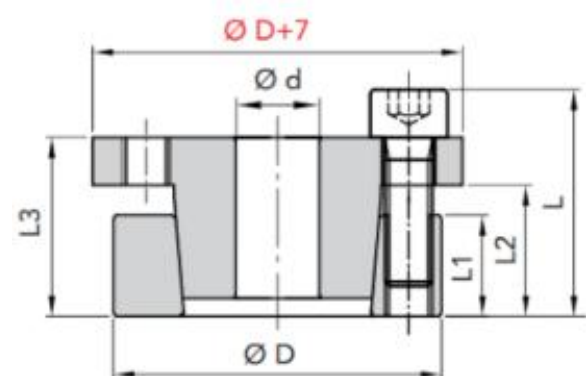


06152040

RCK 15 - Self centring

2D Technical Drawing

Dynamic 3D View
Technical Specifications

Part number (CODE)	06152040
Ød (DD) mm	40
ØD (D) mm	80
L1 (L1) mm	20
L2 (L2) mm	25
L3 (L3) mm	33
L (L) mm	41
Maximum torque Mt (MT) Nm	1440
Clamping pressure - Shaft (CPS) N/mm ²	238
Clamping pressure - Hub (CPH) N/mm ²	120
Clamping screws DIN 912 MAT. 12.9 - Num. (CSN)	7
Clamping screws DIN 912 MAT. 12.9 - Type (CST)	M8x25
Clamping screws DIN 912 MAT. 12.9 - Torque (CSTQ) Nm	41
Extraction thread - Type (ETT)	M8
Extraction thread - Num. (ETN)	3
Weight (WEIGHT) kg	0.90